

Magnetic Stand

Item number: 7010S-10

Images




Description

- V-block base type.

Features

Magnetic force:	600 N vertical retractile force
Clamping device:	magnetic
Clamping force (vertical):	600 N
Base size (LxWxH):	59 x 50 x 55 mm
Total height:	232 mm
Fine adjustment:	None
Stem hole ø:	3/8" / 9.53 mm, 4 mm, 8 mm (with stem bush)
Working radius:	165.0 mm
Delivered:	In a carton box with stem bush 02AZC291
Thread Arm/Base:	M8 x 1.25
Mass:	1.38 kg

Dimensions

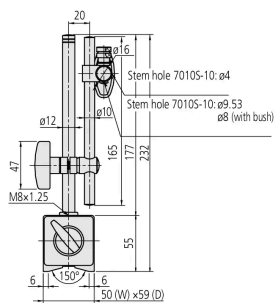

Accessories

Optional accessories:

Cross arm for Magnet Stand

300mm

Art No. 02AZC282

Suggested retail price: 24.00 €*



Standard accessories:

Stem Bush for Magnet Stand

9,53mm to 8mm

Art No. 02AZC291

Suggested retail price: 16.00 €*

