

Dial Indicator Depth Gauge

Item number: 7211A

Images



Description


This rectangular base dial indicator depth gauge offers you the following benefits:

- It has a hardened, precision ground and micro-lapped reference face on its base.

Features

| | |
|------------------------|---|
| Inch-Metric: | Metric |
| Digital/Analog: | Analog |
| Graduation: | 0,01 mm |
| Accuracy: | $\pm 15 \mu\text{m}$ |
| Stroke: | 10 mm |
| Base flatness: | $5 \mu\text{m}$ |
| Probe tip: | Ball, R = 1.5 mm (No. 21JAA224) |
| Extension rods: | 10, 20, 30, 30, 100 mm |
| Mass: | 260 g |
| Delivered: | In a box with spindle lifting lever, with carbide tipped ball point contact element (21JAA224), extension rods (5 pcs.) |

Dimensions

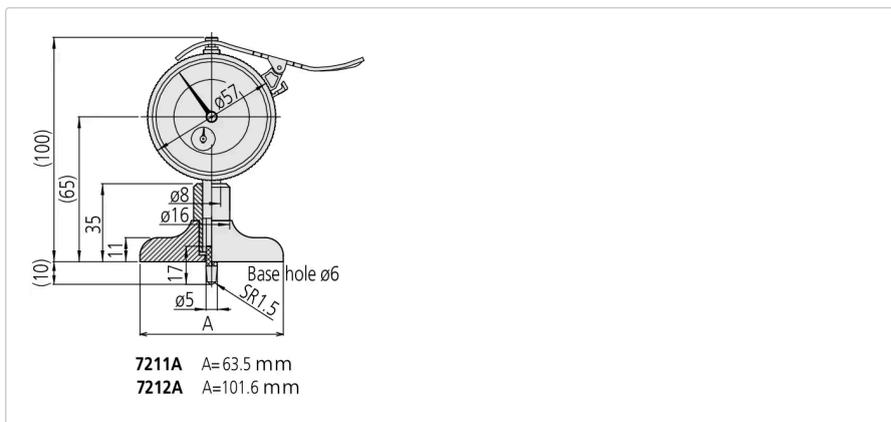

Accessories

Optional accessories:



Limit Hands (green) 2pcs

Dial Indicator Series 2/3/4

Art No. 21AZB195

Price on application



Bezel Clamp for Dial Gauge

Metric, Series 2/3/4

Art No. 21AZB148

Price on application