


## Dial Indicator Depth Gauge

Item number: 7212A

### Images

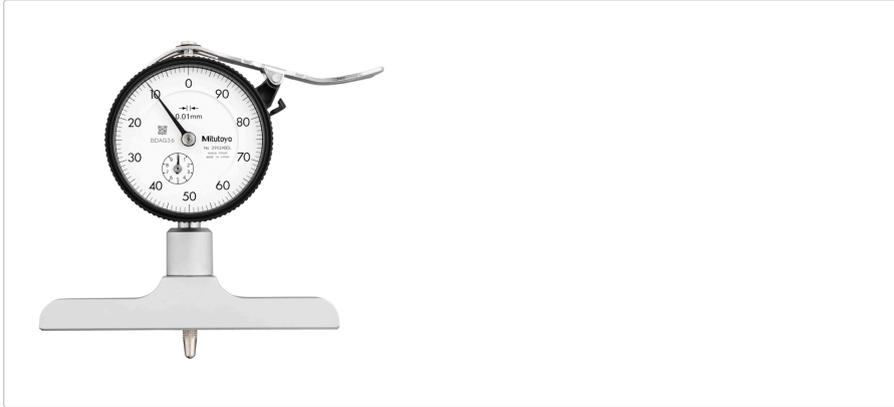

### Description


This rectangular base dial indicator depth gauge offers you the following benefits:

- It has a hardened, precision ground and micro-lapped reference face on its base.

### Features

<b>Inch-Metric:</b>	Metric
<b>Digital/Analog:</b>	Analog
<b>Graduation:</b>	0,01 mm
<b>Accuracy:</b>	±15 µm
<b>Stroke:</b>	10 mm
<b>Base flatness:</b>	5 µm
<b>Probe tip:</b>	Ball, R = 1.5 mm (No. 21JAA224)
<b>Extension rods:</b>	10, 20, 30, 30, 100 mm
<b>Mass:</b>	310 g
<b>Functions:</b>	With indicator No. 2902AB
<b>Delivered:</b>	In a box with spindle lifting lever, with carbide tipped ball point contact element (21JAA224), extension rods (5 pcs.)

### Dimensions

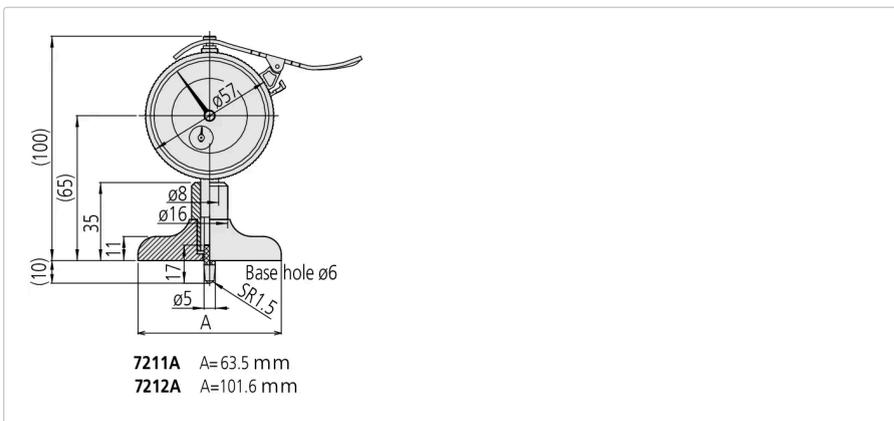

### Accessories

Optional accessories:



## Limit Hands (green) 2pcs

Dial Indicator Series 2/3/4

Art No. 21AZB195

Price on application



## Bezel Clamp for Dial Gauge

Metric, Series 2/3/4

Art No. 21AZB148

Price on application



## Dial Gauge, Flat Back, ISO Type

Reverse Dial Face, 10mm, 0,01mm

Art No. 2902AB

Suggested retail price: 85.00 €\*