


Dial Indicator Depth Gauge

Item number: 7214A

Images

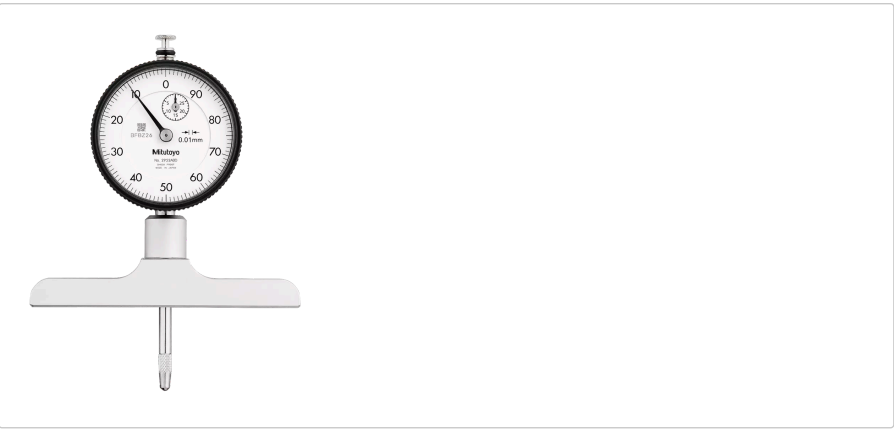

Description


This rectangular base dial indicator depth gauge offers you the following benefits:

- It has a hardened, precision ground and micro-lapped reference face on its base.

Features

Inch-Metric:	Metric
Digital/Analog:	Analog
Graduation:	0,01 mm
Accuracy:	±30 μm
Stroke:	30 mm
Base flatness:	5 μm
Probe tip:	Ball, R = 1.5 mm (No. 21JAA225)
Extension rods:	30, 60, 90 mm
Mass:	310 g
Delivered:	In a box without spindle lifting lever, with carbide tipped ball point contact element (21JAA225), extension rods (3 pcs.)

Dimensions

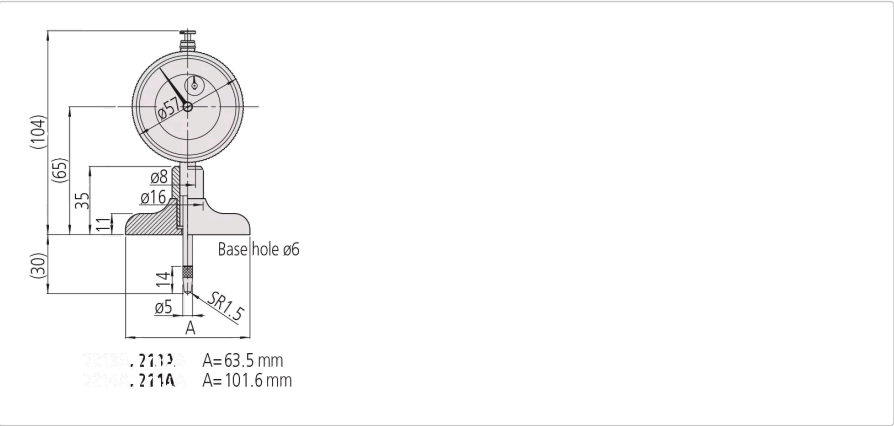

Accessories

Optional accessories:



Limit Hands (green) 2pcs

Dial Indicator Series 2/3/4

Art No. 21AZB195

Price on application



Bezel Clamp for Dial Gauge

Metric, Series 2/3/4

Art No. 21AZB148

Price on application