


Dial Indicator Depth Gauge

Item number: 72175

Images

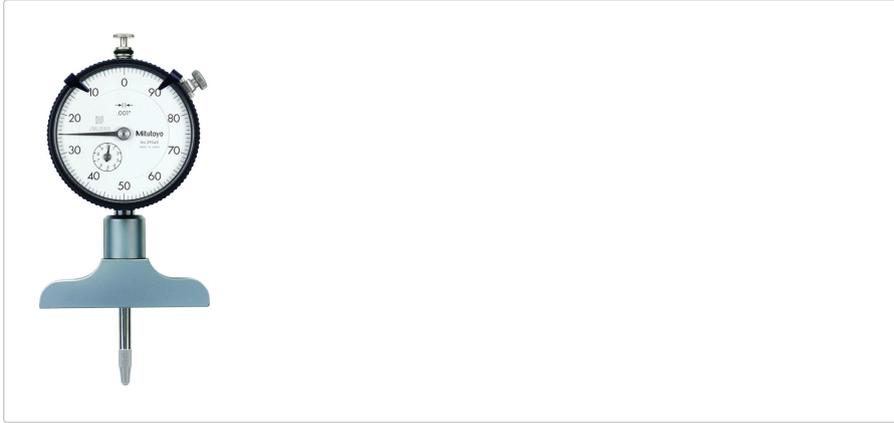

Description

A Mitutoyo depth gauge using stackable extension rods and a 1% stroke dial indicator to cover a wide measuring range, with a lifting lever for rapid operation. The 2.5% base is made from tool steel, hardened and ground with a micro-lapped reference surface.

Features

Inch-Metric:	Inch
Digital/Analog:	Analog
Graduation:	0,001"
Range:	0 - 8 "
Accuracy:	±0.002"
Stroke:	1" mm
Base flatness:	5 μm
Base size :	63.5 x 16 mm
Probe tip:	Ball, R = 1.5 mm (No. 21JZA242)
Extension rods:	1, 2, 4"
Mass:	265 g
Delivered:	In a box without spindle lifting lever, with carbide tipped ball point contact element (21JZA242), extension rods (3 pcs.)

Accessories

Optional accessories:



Limit Hands (green) 2pcs

Dial Indicator Series 2/3/4

Art No. 21AZB195

Price on application



Bezel Clamp for Dial Gauge

Metric, Series 2/3/4

Art No. 21AZB148

Price on application