

Dial Indicator Depth Gauge

Item number: 7221A

Images



Description


This rectangular base dial indicator depth gauge offers you the following benefits:

- It has a hardened, precision ground and micro-lapped reference face on its base.

Features

Inch-Metric:	Metric
Digital/Analog:	Analog
Graduation:	0,01 mm
Accuracy:	±15 μm
Stroke:	10 mm
Base flatness:	5 μm
Probe tip:	Ball, R = 1.5 mm (No. 21JAA224)
Extension rods:	10, 20, 30, 30, 100 mm
Mass:	500 g
Functions:	With indicator No. 2902AB
Delivered:	In a box with spindle lifting lever, with carbide tipped ball point contact element (21JAA224), extension rods (5 pcs.)

Dimensions

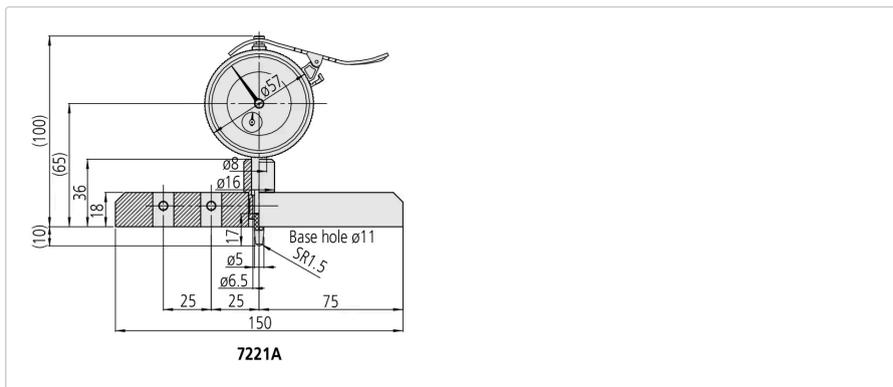

Accessories

Optional accessories:



Limit Hands (green) 2pcs

Dial Indicator Series 2/3/4

Art No. 21AZB195

Price on application



Bezel Clamp for Dial Gauge

Metric, Series 2/3/4

Art No. 21AZB148

Price on application



Dial Gauge, Flat Back, ISO Type

Reverse Dial Face, 10mm, 0,01mm

Art No. 2902AB

Suggested retail price: 85.00 €*