


## Dial Indicator Thickness Gauge

Item number: 7361S

### Images

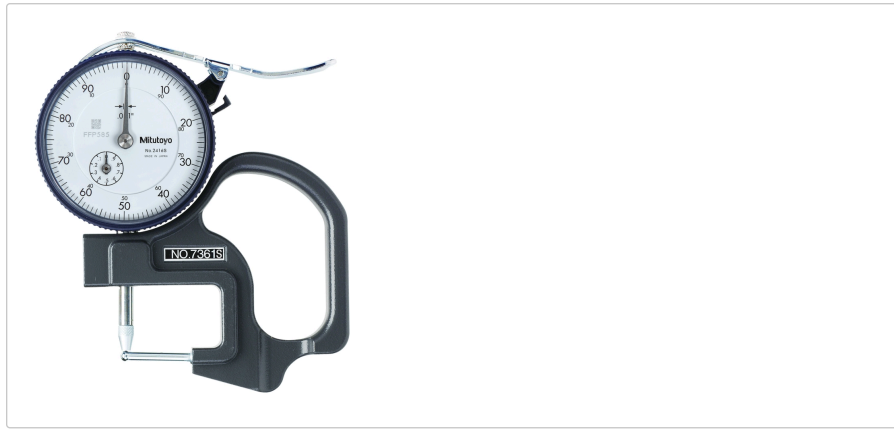

### Description

A Mitutoyo dial-gauge based instrument designed for quick and efficient measurement of small dimensions. The ball anvil and point contact make this model ideally suited for measuring the wall thickness of tubes. The convenient grip handle, thumb trigger and spring-loaded plunger make the instrument easy to use.

### Features

<b>Inch-Metric:</b>	Inch
<b>Functions:</b>	Tube thicknesses - Minimum inside diameter 3,5 mm
<b>Delivered:</b>	In a box with spindle lifting lever 21AZB149
<b>Graduation:</b>	0.001"
<b>Parallelism:</b>	5 $\mu$ m
<b>Max. measuring depth:</b>	0.8"
<b>Mass:</b>	200 g
<b>Contact point:</b>	Thread # 4-48UNF

### Accessories

Optional accessories:

**Limit Hands (green) 2pcs**  
Dial Indicator Series 2/3/4  
Art No. 21AZB195  
Price on application



### Bezel Clamp for Dial Gauge

Metric, Series 2/3/4

Art No. 21AZB148

[Price on application](#)

### Spare parts

#### Consumable spares:



### Spindle Lifting Lever

for S-Type Serie 2,3,4 up to 10mm/0,4"

Art No. 21AZB149

[Price on application](#)



### Spindle Lifting Lever

for S and A-Type Serie 2,3 >10/0,4" up to 20mm/0,8"

Art No. 21AZB150

[Price on application](#)