


Shore Durometer

Item number: 811-336-10

Images

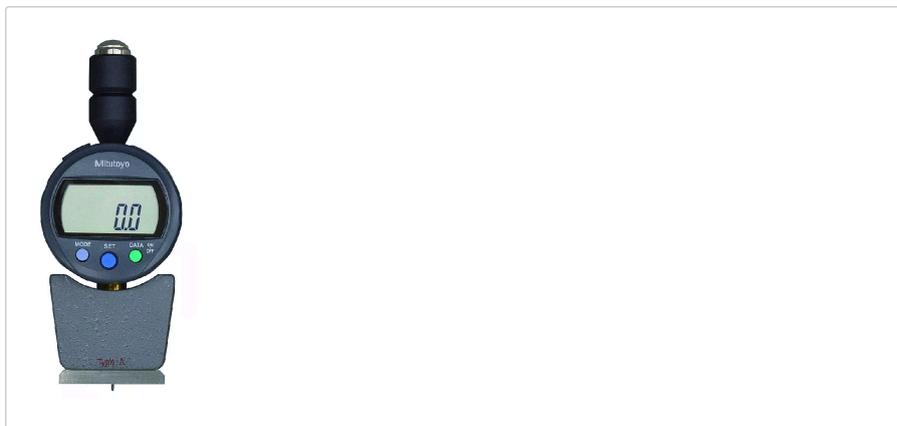

Description

These compact digital/dial durometers in the Shore A scale can test a range of different materials and offer you the following benefits:

- You can use them for testing the hardness of the materials including soft rubber, elastomers, natural rubber, casting resin, neoprene, polyesters, soft PVC, leather, etc.

Features

Model:	HH-336
Model:	HH-336
Shore Scale:	Shore A
Display:	Digital
Indenter b:	ø 1,25 mm
Indenter d:	ø ,079 mm
θ:	35°
Pressure foot a:	ø 3 mm
Pressure foot f:	44 x 18 mm
Indenter protrusion:	2,5 mm
Spring force WE, WA, WD:	WA=550+75 HA [mN]
Dimensions (WxDxH):	151x60x28.5 mm
Mass:	0.29 kg
Connector cable for:	HH-300 Series
PIN:	Flat
U-WAVE-T:	02AZD790F
USB-ITN:	06AFM380F
DP-1VA (264-505):	959149
IT-016U 264-016-10 Hardmatic table:	937387

Accessories

Optional accessories:



Testing stand

HH-300 Series Shore D all types
Art No. 811-012
Suggested retail price: 2,095.00 €*



Testing stand

HH-300 Series Shore A compact types
Art No. 811-013
Suggested retail price: 2,095.00 €*



Testing stand

HH-300 Series Shore A long types
Art No. 811-019
Suggested retail price: 2,095.00 €*



Digimatic Mini Processor DP-1VR

Art No. 264-504
Price on application



Digimatic Cable, Flat Straight Type

1 m
Art No. 905338
Suggested retail price: 37.00 €*



Statistic Processing Printer DP-1VR

CEE Type

Art No. 264-504-5D

Suggested retail price: 463.00 €*
*



35, 60, 85 Shore D Shore Hardness Reference Material Set

Art No. 218000DMIT

Suggested retail price: 287.00 €*
*

Standard accessories:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 7.00 €*
*