

Granite Surface Plate, DIN 876

Item number: 901-127

Images




Description

- Surface diamond lapped, side face fine ground, backside fine sawn.
- The optional stand is a welded construction including 3 or 5-point bearings and two adjusting screws.
- Delivered with a certificate of inspection

Features

Vickers hardness:	HV 850-900
Flexural strength:	13-22 N/mm ²
Compressive strength:	Approx. 280 N/mm ²
Linear coefficient of expansion:	$(5 - 7.5) \times 10^{-6} \times K^{-1}$
Dimensions L x W x H:	1200 x 800 x 160 mm
Accuracy:	DIN 876 grade 0
Max. workpiece load:	1,200 kg
Delivered:	With steel ball inserts and certificate of inspection
Mass:	460 kg

Dimensions

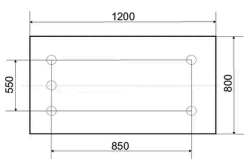

Accessories

Optional accessories:



Stand (Angle Steel), Granite Plate

1200x800x160mm

Art No. 901-935

Suggested retail price: **611.00 €***
