

Granite Surface Plate, DIN 876

Item number: 901-138

Images




Description

- Surface diamond lapped, side face fine ground, backside fine sawn.
- The optional stand is a welded construction including 3 or 5-point bearings and two adjusting screws.
- Delivered with a certificate of inspection

Features

Vickers hardness:	HV 850-900
Flexural strength:	13-22 N/mm ²
Compressive strength:	Approx. 280 N/mm ²
Linear coefficient of expansion:	$(5 - 7.5) \times 10^{-6} \times K^{-1}$
Dimensions L x W x H:	1600 x 1000 x 160 mm
Accuracy:	DIN 876 grade 00
Max. workpiece load:	650 kg
Delivered:	With steel ball inserts and certificate of inspection
Mass:	768 kg

Dimensions

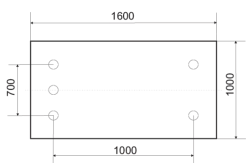

Accessories

Optional accessories:



Stand (Angle Steel), Granite Plate

1600x1000x160mm

Art No. 901-936

Suggested retail price: 761.00 €*
