

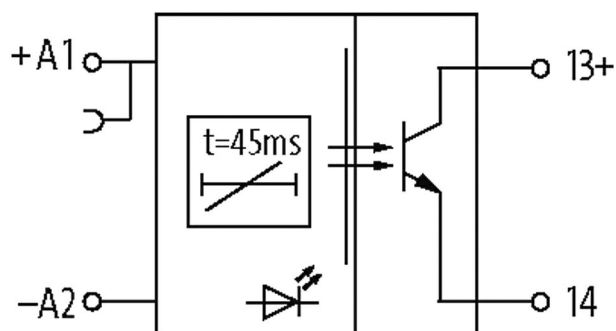
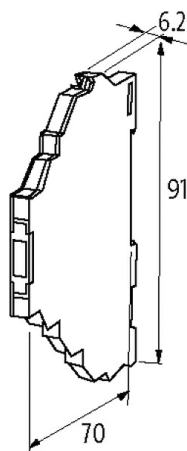
MIRO 6.2 TIMER

Impulsverlängerung 24 VDC / 25 mA / 45 ms

Transistor output

Impulse expansion: 40...45 ms

Spring clamp terminals

Illustration

Product may differ from Image

Output

Switching voltage

2...30 V DC

Switching current per output	max. 25 mA
------------------------------	------------

Min. load current	0.1 mA
-------------------	--------

Switching frequency	max. 20 Hz
---------------------	------------

General data

Test isolation voltage	no galvanic separation
------------------------	------------------------

Dimensions H×W×D	91×6.2×70 mm
------------------	--------------

Mounting method	DIN-rail mountable (EN 60715)
-----------------	-------------------------------

Temperature range	-20...+60 °C (storage temperature -40...+80 °C)
-------------------	---

Commercial data

country of origin	CZ
-------------------	----

customs tariff number	85364110
-----------------------	----------

EAN	4048879411608
-----	---------------

eClass	27210990
--------	----------

Packaging unit	1
----------------	---