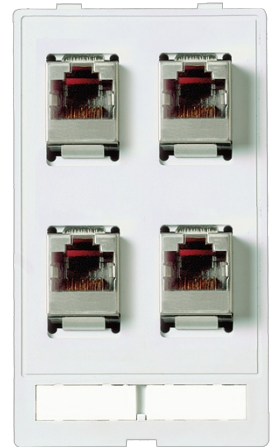


MODLINK MSDD DATA INSERT

4×RJ45

RJ45; RJ45; RJ45; RJ45

4× RJ45, 8-pole metal, CAT5e (female/female)

Illustration

Product may differ from Image

General data

| | |
|------------------|-------------|
| Dimensions H×W×D | 88×51×21 mm |
|------------------|-------------|

RJ45

| | |
|-------------------------------|---------------------------------------|
| Operating voltage (UL Rating) | max. 30 V AC/42.4 V DC |
| Operating current (UL Rating) | max. 175 mA |
| Connection front side | RJ45 |
| Connection rear side | RJ45 |
| Locking of ports | Snap In |
| Specification | CAT5e, Class D, 100 MHz, (EN 50173-1) |

Commercial data

| | |
|-----------------------|---------------|
| country of origin | DE |
| customs tariff number | 85366990 |
| EAN | 4048879037600 |
| eClass | 27189217 |
| Packaging unit | 1 |