

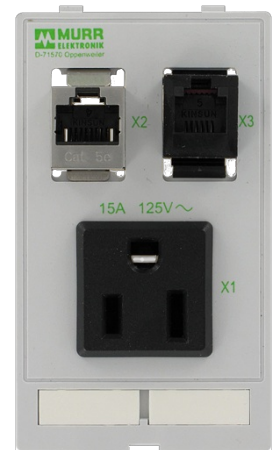
MODLINK MSDD SINGLE COMBI INSERT USA NEMA 5-15

1xRJ45 female/female + 1xRJ12 female/female

1 × NEMA 5-15 (plug-solder connection)

1 × RJ45, 8-pole metal, CAT5e (female/female)

1 × RJ12 (6-pole plastic)

Illustration

Product may differ from Image

General data

Dimensions H×W×D 88×51×25 mm

RJ45

Operating voltage (UL Rating)	max. 30 V AC/42.4 V DC
Operating current (UL Rating)	max. 175 mA
Connection front side	RJ45
Connection rear side	RJ45
Locking of ports	Snap In
Specification	CAT5e, Class D, 100 MHz, (EN 50173-1)

RJ12

Operating voltage	max. 48 V AC/DC
Operating voltage (UL Rating)	max. 30 V AC/42.4 V DC
Operating current	max. 1 A
Operating current (UL Rating)	max. 175 mA
Connection front side	RJ12
Connection rear side	RJ12
Locking of ports	Snap In

USA

Operating voltage	125 V AC
Operating current	15 A
No. of poles	2 + PE
Connection	Plug-solder connection: 4.8×0.5 mm

Commercial data

country of origin	DE
customs tariff number	85366990

EAN	4048879331135
eClass	27189217
Packaging unit	1