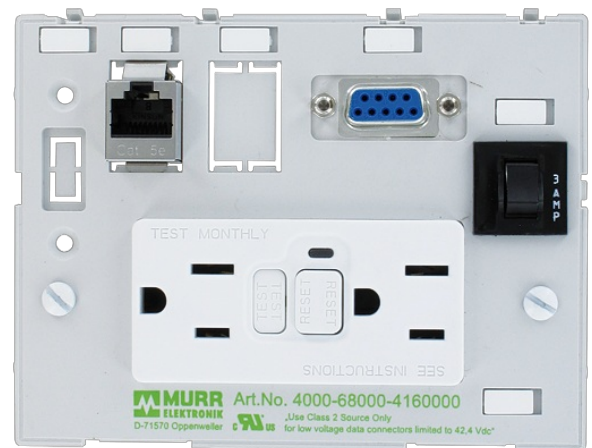


MODLINK MSDD DBL COMBI INSERT USA 2XNEMA 5-15

GFCI+1xRJ45 fem./fem.+1xSUB-D9 fem./fem.+1x3A fuse

2× NEMA-GFCI 5-15 (screw terminals)
 1× RJ45, 8-pole metal, CAT5e (female/female)
 1× SUB-D9 (female/female)
 1× fuse (3 A)
 with touch protection

Illustration

Product may differ from Image

Approvals**General data**

Dimensions H×W×D	88×116×72 mm
------------------	--------------

SUB-D9

Operating voltage	48 V AC/DC
Operating voltage (UL Rating)	max. 30 V AC/42.4 V DC
Operating current	3 A
Operating current (UL Rating)	max. 175 mA
No. of poles	9-pole
Connection front side	SUB-D (female)
Connection rear side	SUB-D (female)
Locking of ports	UNC 4...40 bolt

RJ45

Operating voltage (UL Rating)	max. 30 V AC/42.4 V DC
Operating current (UL Rating)	max. 175 mA
Connection front side	RJ45
Connection rear side	RJ45
Locking of ports	Snap In
Specification	CAT5e, Class D, 100 MHz, (EN 50173-1)

Fuse

Operating voltage	250 V AC/32 V DC
-------------------	------------------

Continuous load	3 A
-----------------	-----

USA

Operating voltage	125 V AC
-------------------	----------

Operating current	15 A
-------------------	------

No. of poles	2 + PE
--------------	--------

Connection	Screw terminals: max. 2× 6 mm ² (AWG 10)
------------	---

Commercial data

country of origin	CN
-------------------	----

customs tariff number	85366990
-----------------------	----------

EAN	4048879462846
-----	---------------

eClass	27189217
--------	----------

Packaging unit	1
----------------	---
