

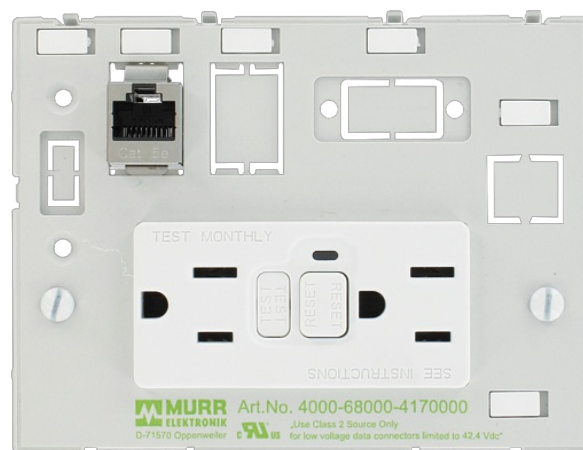
MODLINK MSDD DBL COMBI INSERT USA 2XNEMA 5-15

GFCI+1xRJ45 female/female

2× NEMA-GFCI 5-15 (screw terminals)

1× RJ45, 8-pole metal, CAT5e (female/female)

with touch protection

Illustration

Product may differ from Image

Approvals**General data**

Dimensions H×W×D 88×116×72 mm

RJ45

Operating voltage (UL Rating) max. 30 V AC/42.4 V DC

Operating current (UL Rating) max. 175 mA

Connection front side RJ45

Connection rear side RJ45

Locking of ports Snap In

Specification CAT5e, Class D, 100 MHz, (EN 50173-1)

USA

Operating voltage 125 V AC

Operating current 15 A

No. of poles 2 + PE

Connection Screw terminals: max. 2× 6 mm² (AWG 10)**Commercial data**

country of origin DE

customs tariff number 85366990

EAN 4048879463690

eClass 27189217

Packaging unit 1

