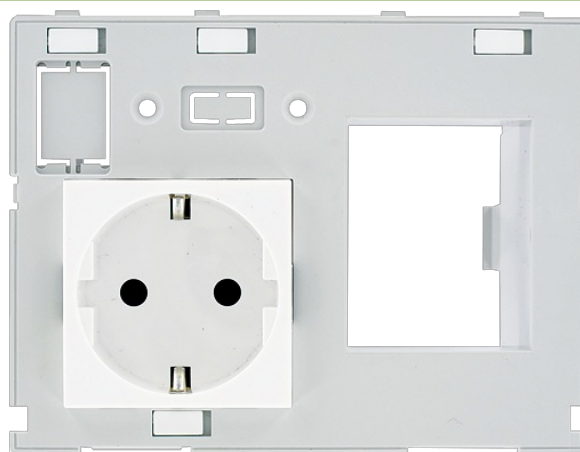


MODLINK MSDD DBL COMBI INSERT GERMANY

RCD opening

1 × Germany (VDE) white

1 × FI cut-out

Illustration

Product may differ from Image

General data

Dimensions H×W×D 88×116×70 mm

Shielding plate

Connection Threaded hole M4

Tightening torque 0.9 Nm ±0.1

Germany (VDE)

Operating voltage 250 V AC

Operating current 16 A

No. of poles 2 + PE

Connection Spring clamp terminals: max. 2× 2.5 mm² (AWG 14)**Commercial data**

country of origin DE

customs tariff number 85366990

EAN 4048879369350

eClass 27189217

Packaging unit 1