

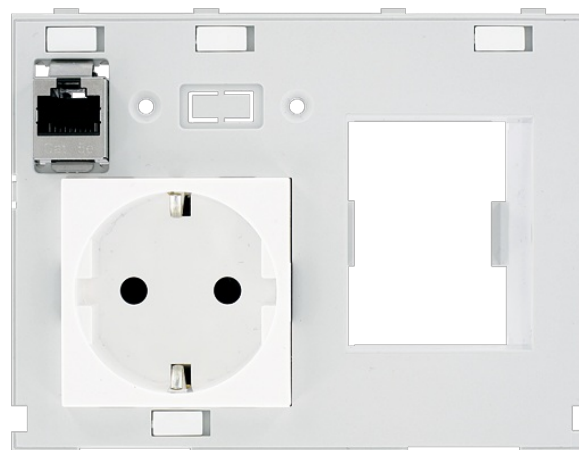
MODLINK MSDD DBL COMBI INSERT GERMANY

1xRJ45 fem./fem. + RCD opening

1 × Germany (VDE) white

1 × RJ45, 8-pole metal, CAT5e (female/female)

1 × FI cut-out

Illustration

Product may differ from Image

General data

Dimensions H×W×D	88×116×70 mm
------------------	--------------

RJ45

Operating voltage (UL Rating)	max. 30 V AC/42.4 V DC
Operating current (UL Rating)	max. 175 mA
Connection front side	RJ45
Connection rear side	RJ45
Locking of ports	Snap In
Specification	CAT5e, Class D, 100 MHz, (EN 50173-1)

Germany (VDE)

Operating voltage	250 V AC
Operating current	16 A
No. of poles	2 + PE
Connection	Spring clamp terminals: max. 2× 2.5 mm ² (AWG 14)

Commercial data

country of origin	DE
customs tariff number	85366990
EAN	4048879384193
eClass	27189217
Packaging unit	1