

MODLINK MSDD DBL COMBI INSERT GERMANY

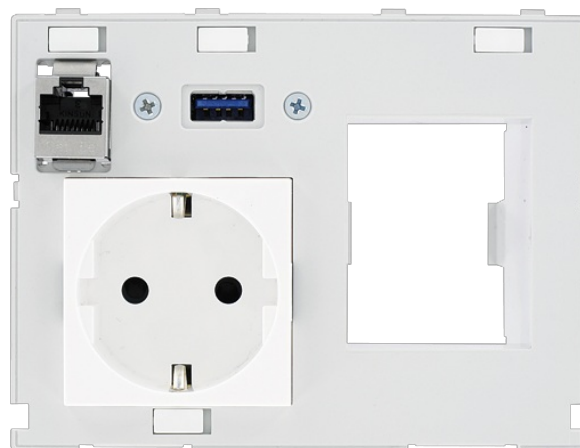
1xRJ45+USB-A + RCD opening

1 × Germany (VDE) white

1 × USB 3.0 (female/female) form A

1 × RJ45, 8-pole metal, CAT5e (female/female)

1 × FI cut-out

Illustration

Product may differ from Image

General data

Dimensions H×W×D	88×116×70 mm
------------------	--------------

RJ45

Operating voltage (UL Rating)	max. 30 V AC/42.4 V DC
Operating current (UL Rating)	max. 175 mA
Connection front side	RJ45
Connection rear side	RJ45
Locking of ports	Snap In
Specification	CAT5e, Class D, 100 MHz, (EN 50173-1)

USB

Operating voltage	48 V AC/DC
Operating voltage (UL Rating)	max. 30 V AC/42.4 V DC
Operating current	1.5 A
Locking of ports	Snap In
Specification	USB: 3.0 (max. 5 Gbit/s)

Germany (VDE)

Operating voltage	250 V AC
Operating current	16 A
No. of poles	2 + PE
Connection	Spring clamp terminals: max. 2× 2.5 mm² (AWG 14)

Commercial data

country of origin	CZ
customs tariff number	85366990
EAN	4048879401869

eClass	27189217
Packaging unit	1