

MODLINK MSDD DBL COMBI INSERT GREAT BRITAIN

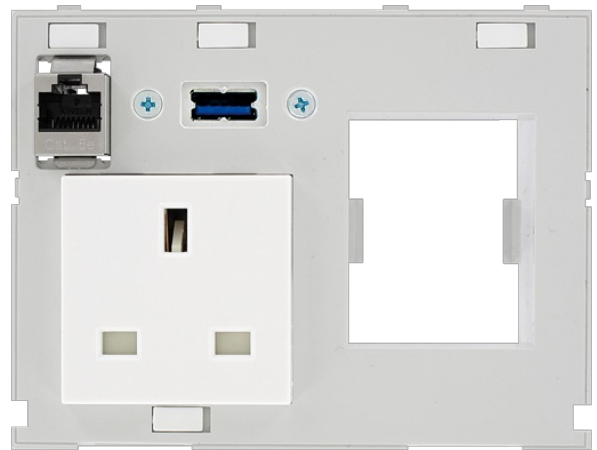
1xUSB, 1xRJ45 fem./fem. + RCD opening

1× Great Britain (BS)

1× RJ45, 8-pole metal, CAT5e (female/female)

1× FI cut-out

1× USB 3.0 (female/female) form A

Illustration

Product may differ from Image

General data

Dimensions H×W×D	88×116×70 mm
------------------	--------------

RJ45

Operating voltage (UL Rating)	max. 30 V AC/42.4 V DC
Operating current (UL Rating)	max. 175 mA
Connection front side	RJ45
Connection rear side	RJ45
Locking of ports	Snap In
Specification	CAT5e, Class D, 100 MHz, (EN 50173-1)

USB

Operating voltage	48 V AC/DC
Operating voltage (UL Rating)	max. 30 V AC/42.4 V DC
Operating current	1.5 A
Locking of ports	Snap In
Specification	USB: 3.0 (max. 5 Gbit/s)

England (BS)

Operating voltage	250 V AC
Operating current	13 A
No. of poles	2 + PE
Connection	Screw terminals: max. 2× 4 mm ² (AWG 12)

Commercial data

country of origin	DE
customs tariff number	85366990
EAN	4048879547079

eClass 27189217

Packaging unit 1