

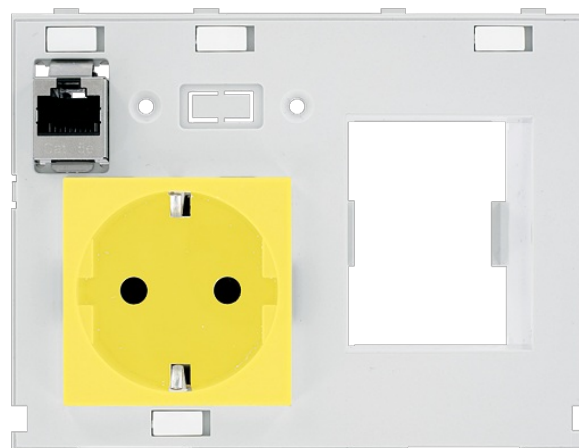
MODLINK MSDD DBL COMBI INSERT GERMANY YELLOW

1xRJ45 fem./fem. + RCD opening

1x VDE yellow

1x RJ45, 8-pole metal, CAT5e (female/female)

1x FI cut-out

Illustration

Product may differ from Image

General data

Dimensions H×W×D 88×116×70 mm

RJ45

Operating voltage (UL Rating) max. 30 V AC/42.4 V DC

Operating current (UL Rating) max. 175 mA

Connection front side RJ45

Connection rear side RJ45

Locking of ports Snap In

Specification CAT5e, Class D, 100 MHz, (EN 50173-1)

Germany (VDE)

Operating voltage 250 V AC

Operating current 16 A

No. of poles 2 + PE

Connection Spring clamp terminals: max. 2× 2.5 mm² (AWG 14)**Commercial data**

country of origin DE

customs tariff number 85366990

EAN 4048879402019

eClass 27189217

Packaging unit 1