


**Modlink MSDD-set: Frame 4000-68122-0000000,**  
insert 4000-68000-1400000 + 4000-68000-0010000

**Illustration**

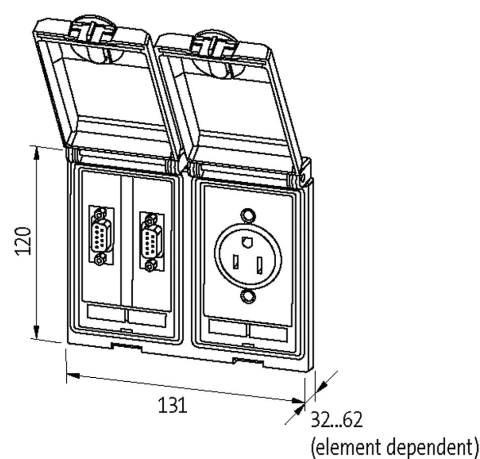

Product may differ from Image

**Frame**

|                                           |                                                 |
|-------------------------------------------|-------------------------------------------------|
| suitable for mounting with wall thickness | 1...5 mm                                        |
| Protection                                | IP65                                            |
| Housing                                   | Zinc die-casting, KTL coated                    |
| Temperature range                         | -10...+60 °C (storage temperature -25...+60 °C) |

**SUB-D9**

|                               |                        |
|-------------------------------|------------------------|
| Operating voltage             | 48 V AC/DC             |
| Operating voltage (UL Rating) | max. 30 V AC/42.4 V DC |
| Operating current             | 3 A                    |
| Operating current (UL Rating) | max. 175 mA            |
| No. of poles                  | 9-pole                 |
| Connection front side         | SUB-D (female)         |
| Connection rear side          | SUB-D (male)           |
| Locking of ports              | UNC 4...40 bolt        |

**RJ45**

|                               |                                       |
|-------------------------------|---------------------------------------|
| Operating voltage (UL Rating) | max. 30 V AC/42.4 V DC                |
| Operating current (UL Rating) | max. 175 mA                           |
| Connection front side         | RJ45                                  |
| Connection rear side          | RJ45                                  |
| Locking of ports              | Snap In                               |
| Specification                 | CAT5e, Class D, 100 MHz, (EN 50173-1) |

**Shielding plate**

|                   |                  |
|-------------------|------------------|
| Connection        | Threaded hole M4 |
| Tightening torque | 0.9 Nm $\pm$ 0.1 |

**USB**

|                   |            |
|-------------------|------------|
| Operating voltage | 48 V AC/DC |
|-------------------|------------|

|                               |                            |
|-------------------------------|----------------------------|
| Operating voltage (UL Rating) | 42.4 V DC                  |
| Operating current             | max. 500 mA                |
| Locking of ports              | Snap In                    |
| Specification                 | USB: 2.0 (max. 480 Mbit/s) |

**Germany (VDE)**

|                   |                                                     |
|-------------------|-----------------------------------------------------|
| Operating voltage | 250 V AC                                            |
| Operating current | 16 A                                                |
| No. of poles      | 2 + PE                                              |
| Connection        | Screw terminals: max. 2× 6 mm <sup>2</sup> (AWG 10) |
| LED display       | yellow                                              |

**Commercial data**

|                       |               |
|-----------------------|---------------|
| country of origin     | CZ            |
| customs tariff number | 85389099      |
| EAN                   | 4048879035385 |
| eClass                | 27189217      |
| Packaging unit        | 1             |