


Modlink MSDD-set: Frame 4000-68122-0000000,
insert 4000-68000-1600000 + 4000-68000-0010000

Illustration

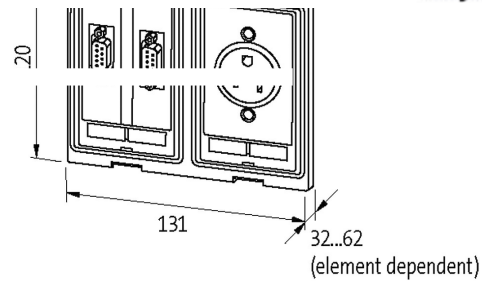

stay connected

Product may differ from Image

Frame

| | |
|---|---|
| suitable for mounting with wall thickness | 1...5 mm |
| Protection | IP65 |
| Housing | Zinc die-casting, KTL coated |
| Temperature range | -10...+60 °C (storage temperature -25...+60 °C) |

SUB-D25

| | |
|-------------------------------|------------------------|
| Operating voltage | 48 V AC/DC |
| Operating voltage (UL Rating) | max. 30 V AC/42.4 V DC |
| Operating current | 3 A |
| Operating current (UL Rating) | max. 175 mA |
| No. of poles | 25-pole |
| Connection front side | SUB-D (female) |
| Connection rear side | SUB-D (male) |
| Locking of ports | UNC 4...40 bolt |

RJ45

| | |
|-------------------------------|---------------------------------------|
| Operating voltage (UL Rating) | max. 30 V AC/42.4 V DC |
| Operating current (UL Rating) | max. 175 mA |
| Connection front side | RJ45 |
| Connection rear side | RJ45 |
| Locking of ports | Snap In |
| Specification | CAT5e, Class D, 100 MHz, (EN 50173-1) |

Shielding plate

| | |
|-------------------|------------------|
| Connection | Threaded hole M4 |
| Tightening torque | 0.9 Nm ±0.1 |

Germany (VDE)

| | |
|-------------------|---|
| Operating voltage | 250 V AC |
| Operating current | 16 A |
| No. of poles | 2 + PE |
| Connection | Screw terminals: max. 2× 6 mm ² (AWG 10) |
| LED display | yellow |

Commercial data

| | |
|-----------------------|---------------|
| country of origin | CZ |
| customs tariff number | 85366990 |
| EAN | 4048879035330 |
| eClass | 27189217 |
| Packaging unit | 1 |