


**Modlink MSDD-set: Frame 4000-68123-0000000,**  
insert 4000-68000-0010000 + 4000-68000-0240000

**Illustration**

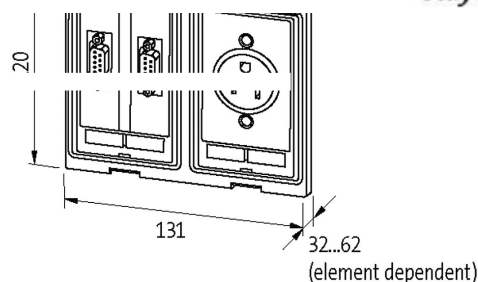

Product may differ from Image

**Frame**

|                                           |                                                 |
|-------------------------------------------|-------------------------------------------------|
| suitable for mounting with wall thickness | 1...5 mm                                        |
| Protection                                | IP65                                            |
| Housing                                   | Zinc die-casting, with surface finishing        |
| Temperature range                         | -10...+60 °C (storage temperature -25...+60 °C) |

**SUB-D9**

|                               |                        |
|-------------------------------|------------------------|
| Operating voltage             | 48 V AC/DC             |
| Operating voltage (UL Rating) | max. 30 V AC/42.4 V DC |
| Operating current             | 3 A                    |
| Operating current (UL Rating) | max. 175 mA            |
| No. of poles                  | 9-pole                 |
| Connection front side         | SUB-D (female)         |
| Connection rear side          | SUB-D (female)         |
| Locking of ports              | UNC 4...40 bolt        |

**Germany (VDE)**

|                   |                                                     |
|-------------------|-----------------------------------------------------|
| Operating voltage | 250 V AC                                            |
| Operating current | 16 A                                                |
| No. of poles      | 2 + PE                                              |
| Connection        | Screw terminals: max. 2× 6 mm <sup>2</sup> (AWG 10) |
| LED display       | yellow                                              |

**Commercial data**

|                       |               |
|-----------------------|---------------|
| country of origin     | CZ            |
| customs tariff number | 85389099      |
| EAN                   | 4048879035217 |
| eClass                | 27189217      |
| Packaging unit        | 1             |