


**Modlink MSDD-set: Frame 4000-68123-0000000,**  
insert 4000-68000-0020000 + 4000-68000-1540000

**Illustration**



stay connected

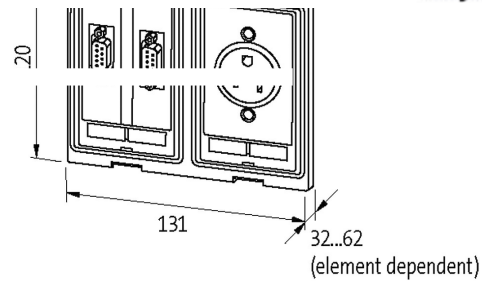

Product may differ from Image

### Frame

suitable for mounting with wall thickness	1...5 mm
Protection	IP65
Housing	Zinc die-casting, with surface finishing
Temperature range	-10...+60 °C (storage temperature -25...+60 °C)

### SUB-D9

Operating voltage	48 V AC/DC
Operating voltage (UL Rating)	max. 30 V AC/42.4 V DC
Operating current	3 A
Operating current (UL Rating)	max. 175 mA
No. of poles	9-pole
Connection front side	SUB-D (male)
Connection rear side	SUB-D (male)
Locking of ports	UNC 4...40 bolt

### RJ45

Operating voltage (UL Rating)	max. 30 V AC/42.4 V DC
Operating current (UL Rating)	max. 175 mA
Connection front side	RJ45
Connection rear side	RJ45
Locking of ports	Snap In
Specification	CAT5e, Class D, 100 MHz, (EN 50173-1)

### PS2

Operating voltage	30 V AC/DC
Operating current	1 A
No. of poles	6-pole
Connection cross section	max. 0.5 mm <sup>2</sup> (AWG 20)
Connection front side	PS2 (female)
Connection rear side	PS2 (solder connection)
Locking of ports	Screw locking

### Germany (VDE)

Operating voltage	250 V AC
Operating current	16 A
No. of poles	2 + PE
Connection	Screw terminals: max. 2× 6 mm <sup>2</sup> (AWG 10)

### Commercial data

country of origin	CZ
customs tariff number	85366990
EAN	4048879034791
eClass	27189217
Packaging unit	1

