


Modlink MSDD-set: Frame 4000-68123-0000000,
insert 4000-68000-0030000 + 4000-68000-0310000

Illustration

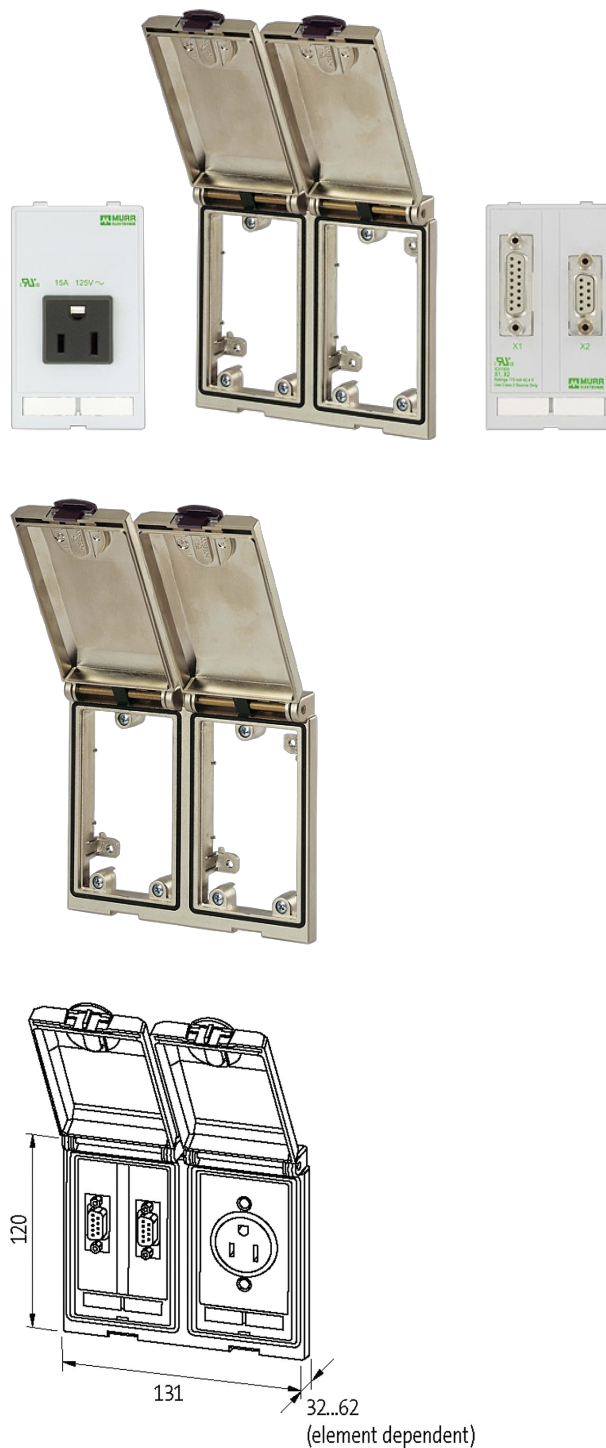

Product may differ from Image

Frame

suitable for mounting with wall thickness	1...5 mm
Protection	IP65
Housing	Zinc die-casting, with surface finishing

The information in this brochure has been compiled with the utmost care.

Liability for the correctness completeness and topicality of the information is restricted to gross negligence. Version: 10/20

Temperature range -10...+60 °C (storage temperature -25...+60 °C)

SUB-D15 HD

Operating voltage (UL Rating)	max. 30 V AC/42.4 V DC
Operating current (UL Rating)	max. 175 mA
No. of poles	15-pole
Connection front side	SUB-D (female)
Connection rear side	SUB-D (solder connection)
Locking of ports	UNC 4...40 bolt

SUB-D9

Operating voltage	48 V AC/DC
Operating voltage (UL Rating)	max. 30 V AC/42.4 V DC
Operating current	3 A
Operating current (UL Rating)	max. 175 mA
No. of poles	9-pole
Connection front side	SUB-D (female)
Connection rear side	SUB-D (solder connection)
Locking of ports	UNC 4...40 bolt

USA

Operating voltage	125 V AC
Operating current	15 A
No. of poles	2 + PE
Connection	Plug-solder connection: 4.8×0.5 mm

Commercial data

country of origin	CZ
customs tariff number	85389099
EAN	4048879034760
eClass	27189217
Packaging unit	1