


**Modlink MSDD-set: Frame 4000-68123-0000000,**  
insert 4000-68000-0090000 + 4000-68000-1210000

**Illustration**

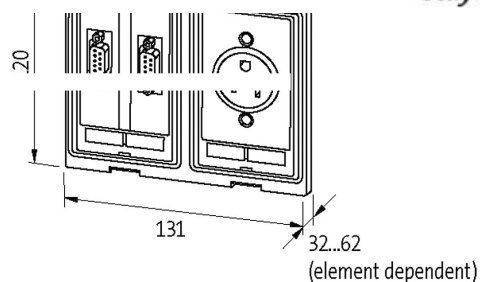

Product may differ from Image

**Frame**

|                                           |                                                 |
|-------------------------------------------|-------------------------------------------------|
| suitable for mounting with wall thickness | 1...5 mm                                        |
| Protection                                | IP65                                            |
| Housing                                   | Zinc die-casting, with surface finishing        |
| Temperature range                         | -10...+60 °C (storage temperature -25...+60 °C) |

**RJ45**

|                               |                                       |
|-------------------------------|---------------------------------------|
| Operating voltage (UL Rating) | max. 30 V AC/42.4 V DC                |
| Operating current (UL Rating) | max. 175 mA                           |
| Connection front side         | RJ45                                  |
| Connection rear side          | RJ45                                  |
| Locking of ports              | Snap In                               |
| Specification                 | CAT5e, Class D, 100 MHz, (EN 50173-1) |

**Australia**

|                   |                                                      |
|-------------------|------------------------------------------------------|
| Operating voltage | 240 V AC                                             |
| Operating current | 15 A                                                 |
| No. of poles      | 2 + PE                                               |
| Connection        | Screw terminals: max. 2 × 4 mm <sup>2</sup> (AWG 12) |

**Commercial data**

|                       |               |
|-----------------------|---------------|
| country of origin     | CZ            |
| customs tariff number | 85389099      |
| EAN                   | 4048879378062 |
| eClass                | 27189217      |
| Packaging unit        | 1             |