


Modlink MSDD-set: Frame 4000-68123-0000000,
insert 4000-68000-0140000 + 4000-68000-1310000

Illustration



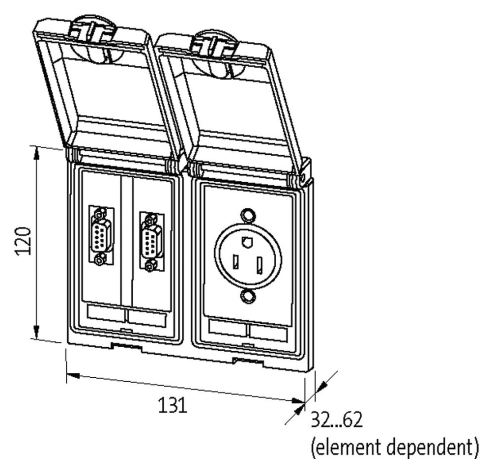

Product may differ from Image

Frame

suitable for mounting with wall thickness	1...5 mm
Protection	IP65
Housing	Zinc die-casting, with surface finishing
Temperature range	-10...+60 °C (storage temperature -25...+60 °C)

RJ45

Operating voltage (UL Rating)	max. 30 V AC/42.4 V DC
Operating current (UL Rating)	max. 175 mA
Connection front side	RJ45
Connection rear side	RJ45
Locking of ports	Snap In
Specification	CAT5e, Class D, 100 MHz, (EN 50173-1)

Shielding plate

Connection	Threaded hole M4
Tightening torque	0.9 Nm $\pm$ 0.1

USB

Operating voltage	48 V AC/DC
Operating voltage (UL Rating)	max. 30 V AC/42.4 V DC
Operating current	1.5 A
Locking of ports	Snap In
Specification	USB: 3.0 (max. 5 Gbit/s)

Germany (VDE)

Operating voltage	250 V AC
Operating current	10...16 A
No. of poles	2 + PE
Connection	Spring clamp terminals: max. 2 $\times$ 2.5 mm ² (AWG 14)

Commercial data	
country of origin	CZ
customs tariff number	85366990
EAN	4048879034555
eClass	27189217
Packaging unit	1