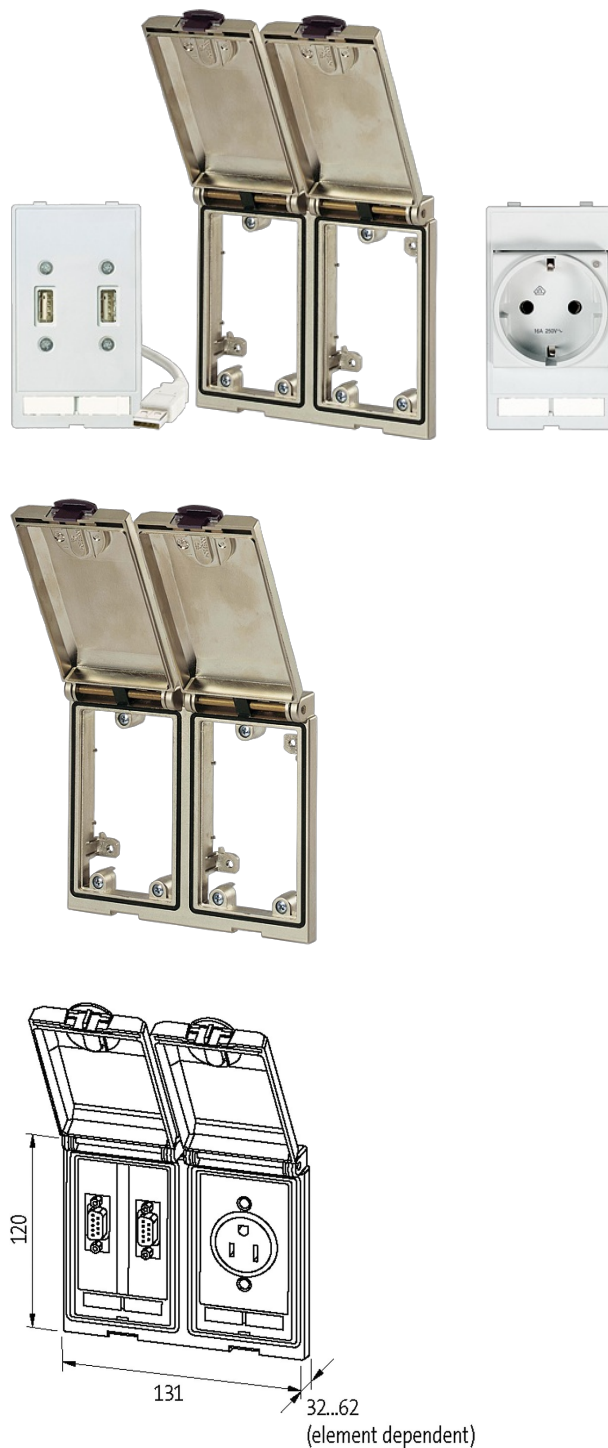


Modlink MSDD-set: Frame 4000-68123-0000000,
insert 4000-68000-0900000 + 4000-68000-0010000

Illustration

Product may differ from Image

Frame

suitable for mounting with wall thickness 1...5 mm

Protection IP65

Housing Zinc die-casting, with surface finishing

Temperature range -10...+60 °C (storage temperature -25...+60 °C)

USB

Operating voltage	48 V AC/DC
Operating voltage (UL Rating)	42.4 V DC
Operating current	max. 500 mA
Locking of ports	Snap In
Specification	USB: 2.0 (max. 480 Mbit/s)

Germany (VDE)

Operating voltage	250 V AC
Operating current	16 A
No. of poles	2 + PE
Connection	Screw terminals: max. 2× 6 mm ² (AWG 10)
LED display	yellow

Commercial data

country of origin	DE
customs tariff number	85366990
EAN	4048879034166
eClass	27189217
Packaging unit	1