


Modlink MSDD-set: Frame 4000-68123-0000000,
insert 4000-68000-1000000 + 4000-68000-0060000

Illustration

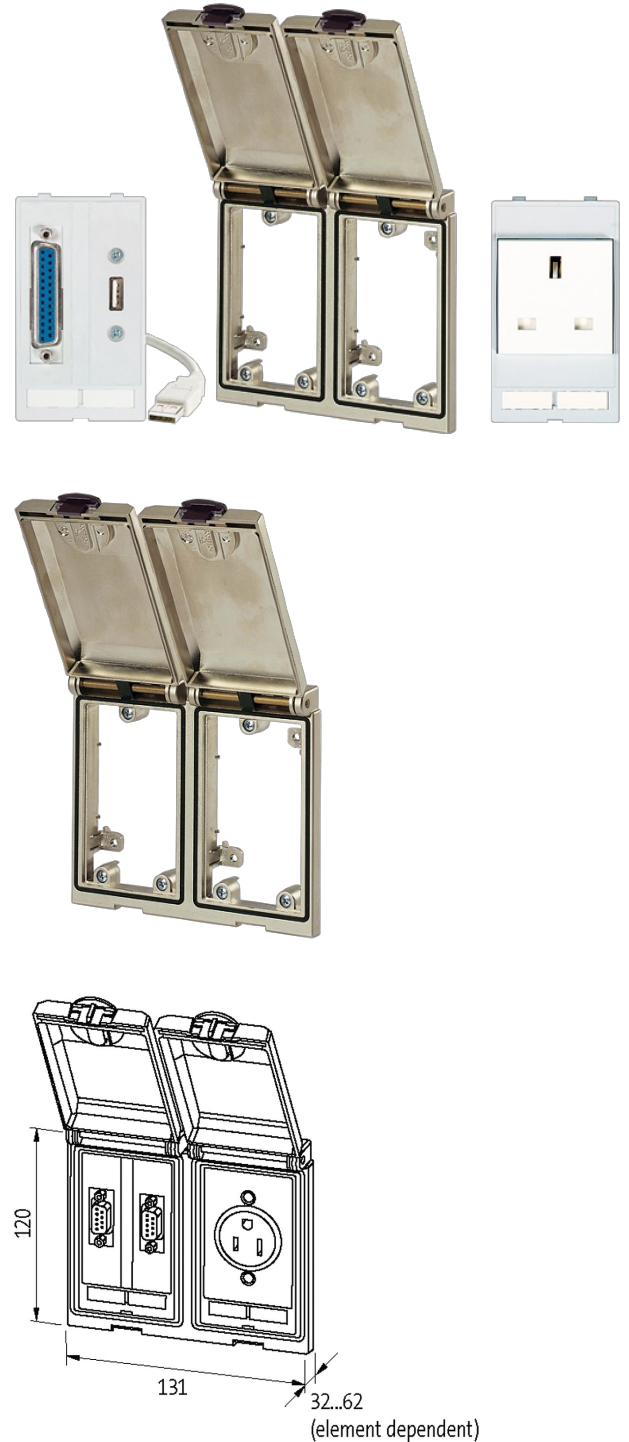

Product may differ from Image

Frame

suitable for mounting with wall thickness 1...5 mm

Protection IP65

Housing Zinc die-casting, with surface finishing

Temperature range -10...+60 °C (storage temperature -25...+60 °C)

SUB-D25

Operating voltage	48 V AC/DC
Operating voltage (UL Rating)	max. 30 V AC/42.4 V DC
Operating current	3 A
Operating current (UL Rating)	max. 175 mA
No. of poles	25-pole
Connection front side	SUB-D (female)
Connection rear side	SUB-D (male)
Locking of ports	UNC 4...40 bolt

USB

Operating voltage	48 V AC/DC
Operating voltage (UL Rating)	42.4 V DC
Operating current	max. 500 mA
Locking of ports	Snap In
Specification	USB: 2.0 (max. 480 Mbit/s)

England (BS)

Operating voltage	250 V AC
Operating current	13 A
No. of poles	2 + PE
Connection	Screw terminals: max. 2× 4 mm ² (AWG 12)

Commercial data

country of origin	CZ
customs tariff number	85366990
EAN	4048879034081
eClass	27189217
Packaging unit	1