


Modlink MSDD-set: Frame 4000-68123-0000000,

insert 4000-68000-1480000

Illustration

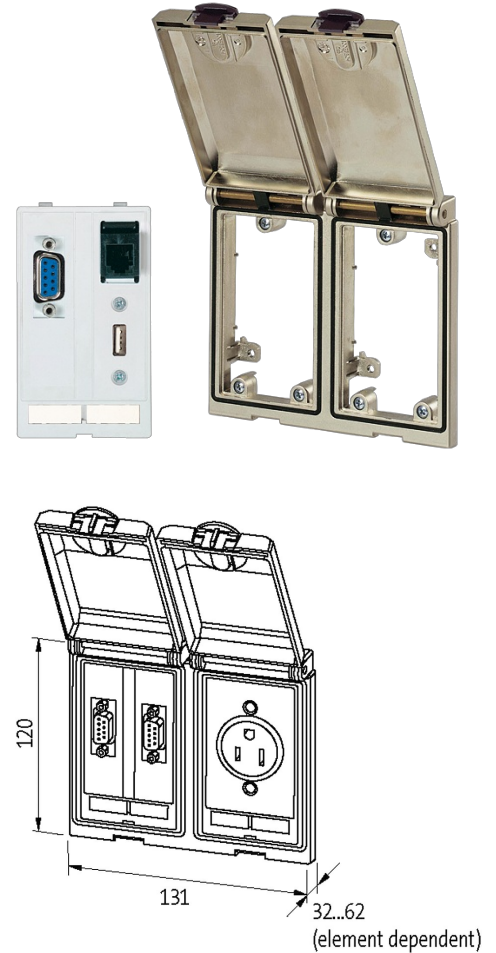

Product may differ from Image

Frame

suitable for mounting with wall thickness	1...5 mm
Protection	IP65
Housing	Zinc die-casting, with surface finishing
Temperature range	-10...+60 °C (storage temperature -25...+60 °C)

SUB-D9

Operating voltage	48 V AC/DC
Operating voltage (UL Rating)	max. 30 V AC/42.4 V DC
Operating current	3 A
Operating current (UL Rating)	max. 175 mA
No. of poles	9-pole
Connection front side	SUB-D (female)
Connection rear side	SUB-D (female)
Locking of ports	UNC 4...40 bolt

RJ12

Operating voltage	max. 48 V AC/DC
-------------------	-----------------

Operating voltage (UL Rating)	max. 30 V AC/42.4 V DC
Operating current	max. 1 A
Operating current (UL Rating)	max. 175 mA
Connection front side	RJ12
Connection rear side	RJ12
Locking of ports	Snap In

Shielding plate

Connection	Threaded hole M4
Tightening torque	0.9 Nm \pm 0.1

USB

Operating voltage	48 V AC/DC
Operating voltage (UL Rating)	42.4 V DC
Operating current	max. 500 mA
Locking of ports	Snap In
Specification	USB: 2.0 (max. 480 Mbit/s)

Commercial data

country of origin	CZ
customs tariff number	85389099
EAN	4048879033718
eClass	27189217
Packaging unit	1