


Modlink MSDD-set: Frame 4000-68223-0000000,
insert 4000-68000-3250000 + 4000-68000-1210000

Illustration

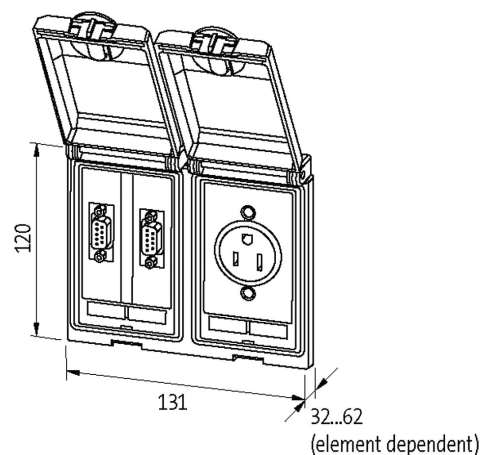

Product may differ from Image

Frame

suitable for mounting with wall thickness	1...5 mm
Protection	IP65
Housing	Frame: zinc die-casting, with surface finishing, Lid: plastic, PC transparent
Temperature range	-10...+60 °C (storage temperature -25...+60 °C)

RJ45

Operating voltage (UL Rating)	max. 30 V AC/42.4 V DC
Operating current (UL Rating)	max. 175 mA
Connection front side	RJ45
Connection rear side	RJ45
Locking of ports	Snap In
Specification	CAT5e, Class D, 100 MHz, (EN 50173-1)

China (CCC)

Operating voltage	250 V AC
Operating current	10 A
No. of poles	2 + PE
Connection	Screw terminals: max. 2 × 4 mm ² (single/stranded wire)

Commercial data

country of origin	DE
customs tariff number	85366990
EAN	4048879330770
eClass	27189217
Packaging unit	1