


**Modlink MSDD-set: Frame 4000-68512-0000003,**

insert 4000-68000-0940000

**Illustration**

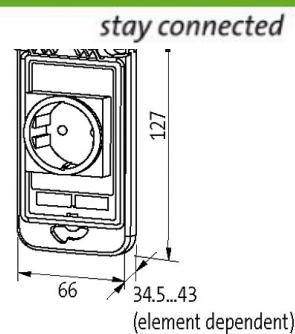

Product may differ from Image

**Frame**

|                                           |                                                      |
|-------------------------------------------|------------------------------------------------------|
| suitable for mounting with wall thickness | 1...5 mm                                             |
| Protection                                | IP65                                                 |
| Housing                                   | Frame: plastic PA black, cap: plastic PC transparent |
| Temperature range                         | -30...+70 °C (storage temperature -30...+80 °C)      |

**RJ45**

|                               |                                       |
|-------------------------------|---------------------------------------|
| Operating voltage (UL Rating) | max. 30 V AC/42.4 V DC                |
| Operating current (UL Rating) | max. 175 mA                           |
| Connection front side         | RJ45                                  |
| Connection rear side          | RJ45                                  |
| Locking of ports              | Snap In                               |
| Specification                 | CAT5e, Class D, 100 MHz, (EN 50173-1) |

**Shielding plate**

|                   |                  |
|-------------------|------------------|
| Connection        | Threaded hole M4 |
| Tightening torque | 0.9 Nm $\pm$ 0.1 |

**USB**

|                               |                          |
|-------------------------------|--------------------------|
| Operating voltage             | 48 V AC/DC               |
| Operating voltage (UL Rating) | max. 30 V AC/42.4 V DC   |
| Operating current             | 1.5 A                    |
| Locking of ports              | Snap In                  |
| Specification                 | USB: 3.0 (max. 5 Gbit/s) |

**Commercial data**

|                       |               |
|-----------------------|---------------|
| country of origin     | DE            |
| customs tariff number | 85366990      |
| EAN                   | 4048879406741 |
| eClass                | 27189217      |
| Packaging unit        | 1             |