


Modlink MSDD set contains:Frame 4000-68514-0000001

Insert 4000-68000-4070000

Illustration

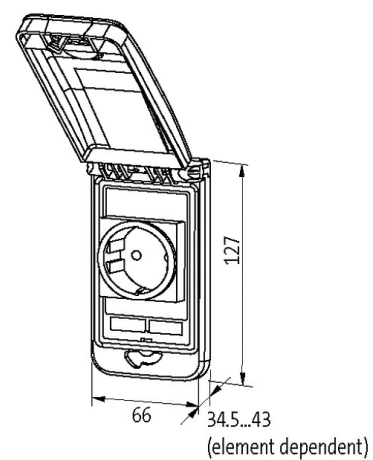

Product may differ from Image

Approvals

**Frame**

suitable for mounting with wall thickness	1...5 mm
Protection	IP65
Housing	Frame: plastic PA black, cap: plastic PBT gray
Temperature range	-30...+70 °C (storage temperature -30...+80 °C)

RJ45

Operating voltage (UL Rating)	max. 30 V AC/42.4 V DC
Operating current (UL Rating)	max. 175 mA
Connection front side	RJ45
Connection rear side	RJ45
Locking of ports	Snap In
Specification	CAT5e, Class D, 100 MHz, (EN 50173-1)

Shielding plate

Connection	Threaded hole M4
Tightening torque	0.9 Nm ±0.1

Fuse

Operating voltage	250 V AC/32 V DC
Continuous load	3 A

USA

Operating voltage	125 V AC
Operating current	15 A
No. of poles	2 + PE
Connection	Plug-solder connection: 4.8×0.5 mm

Commercial data

country of origin	CZ
customs tariff number	85366990
EAN	4048879691857
eClass	27189234
Packaging unit	1