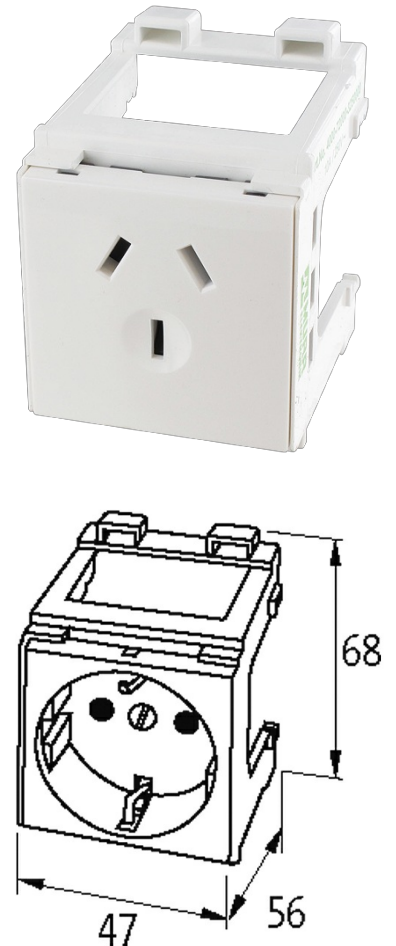


**CHINA SOCKET MODULE**

China (white)  
Screw terminals

**Illustration**

Product may differ from Image

**Approvals****General data**

Mounting method	DIN-rail mountable (EN 60715)
Connection	Screw terminals: max. 2× 4 mm <sup>2</sup> (AWG 12)
Dimensions H×W×D	68×47×57 mm

**Technical Data**

Operating voltage	250 V AC
Operating current	10 A

**Commercial data**

country of origin	FR
-------------------	----

customs tariff number	85366990
EAN	4048879031196
eClass	27143423
Packaging unit	1