

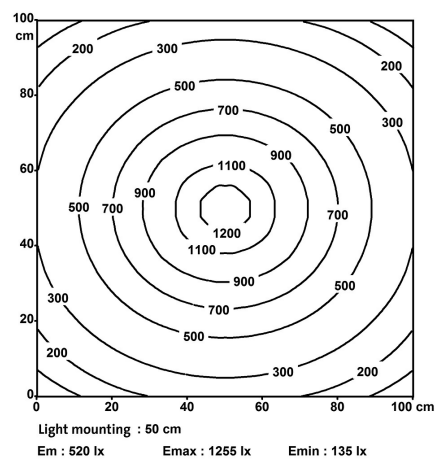
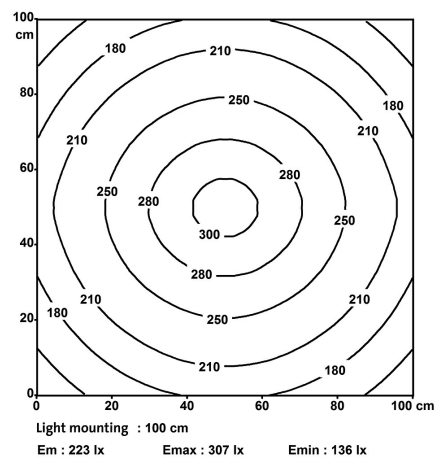
**Modlight Illumix Classic Line C12W**

LED machine lamp, IP67, 24VDC, 2xM12 connection

Modlight Illumix Classic Line C

12 W

expandability

**Illustration**

Product may differ from Image

**Approvals**



#### General data

Relative humidity	5...95%
Protection	IP67
Safety class	III
Mounting method	rotatable
Screw head-Ø	max. 12 mm/M5
Dimensions H×W×D	37×410×40 mm (1.46×16.14×1.57 in)
Temperature range	-30...+50 °C
Material (housing)	Anodized aluminum
Material (light cover)	diffuse single-pane safety glass (ESG), 4 mm
Installation altitude	Operation up to 2 000 m
Vibration stress	2...9 Hz/10 mm; 9...200 Hz/3 g
Shock load	50 g, 11 ms

#### Technical Data

Operating voltage	24 V DC (21.6...27.6 V DC)
Input current	12 W
Connection	M12 (male)
No. of poles	4-pole
Coding	A-coded
Light color	Daylight white, approx. 5500 K
Color reproduction (Ra)	> 80
Luminaire light current	approx. 1260 lm
Luminaire light yield	approx. 105 lm/W
Lighting angle	> 120°

#### Commercial data

country of origin	DE
customs tariff number	94054099
EAN	4048879752435
eClass	27110306
Packaging unit	1