


M8 FEMALE 90° , SHIELDED

PUR 3x0.25 shielded 3m

Female 90°
M8, 3-pole
shielded
with cable sleeves
Further cable lengths on request.
Plastic housings with good resistance against chemicals and oils.
The resistance to aggressive media should be individually tested for your application. Further details on request.

Illustration

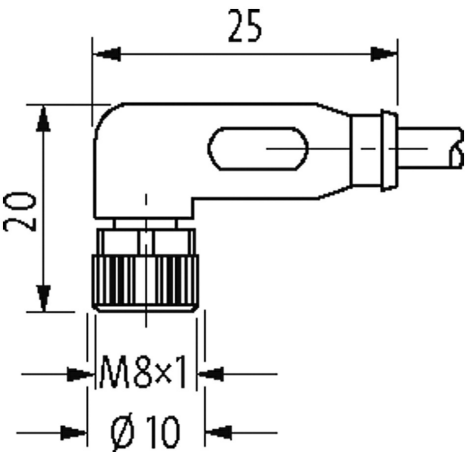

Product may differ from Image

Form

Form 08085

Cables

Cable number	707
No./diameter of wires	3 × 0.25 mm ²
Wire isolation	PP (br, bl, bk)
C-track properties	2 Mio.
Torsion stress	±30 °/m
Jacket Color	black
Material (jacket)	PUR (UL/CSA)
Outer Ø	4.8 mm ±5%
Bend radius (fixed)	5 × outer Ø
Bend radius (moving)	10 × outer Ø
Temperature range (fixed)	-50...+80 °C
Temperature range (mobile)	-25...+80 °C
Shield	yes

Technical Data


stay connected

Operating voltage	max. 60 V AC/DC
Operating current per contact	max. 3 A
Locking of ports	Screw thread (M8×1 mm) recommended torque 0.4 Nm, self-securing
Protection	IP66K, IP67 inserted and tightened (EN 60529)


Commercial data

country of origin	PL
customs tariff number	85444290
EAN	4048879228183
eClass	27061801
Packaging unit	1

Sketch

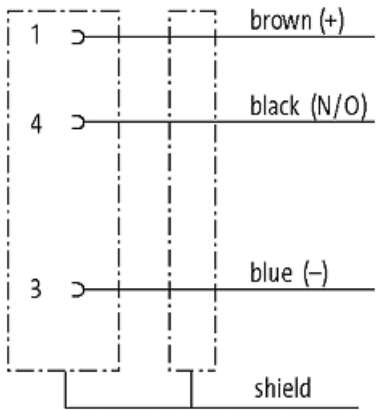

Female

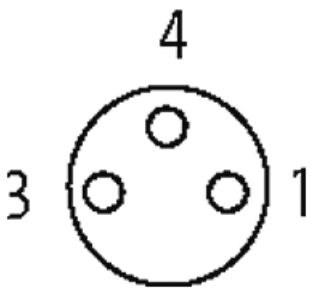

Product may differ from Image