

M8 female receptacle rear mount

wires PP 3x0.25 0,2m

Flange female

M8, 3-pole



Rear mounting

Flange M8 female
with multi-strand wire

3-pole

Illustration

stay connected

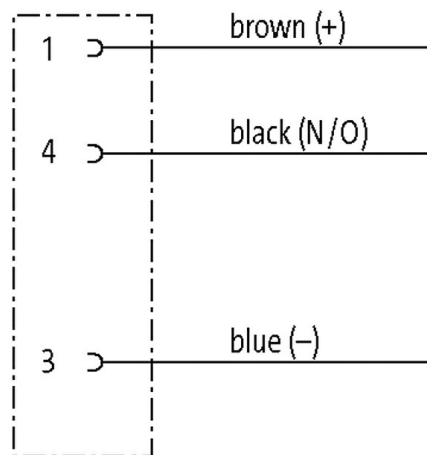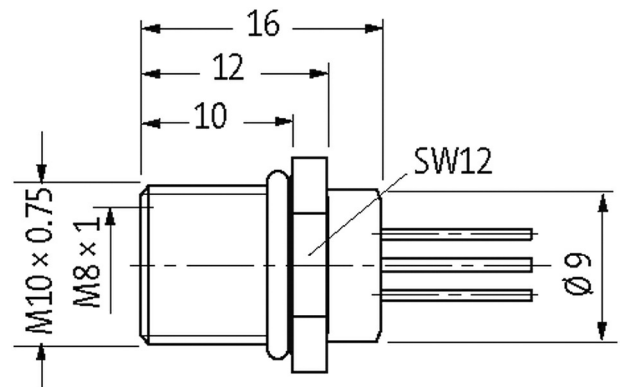

Product may differ from Image

Approvals



Form

Form 08575

General data

Pollution Degree 3

Temperature range -25...+85 °C

Cables

Cable number	970
No./diameter of wires	3 × 0.25 mm ²
Wire isolation	PP (br, bk, bl)
Outer Ø	1.1 mm ±5%
Temperature range (fixed)	-40...+90 °C
Temperature range (mobile)	-25...+90 °C
Bend radius (fixed)	5 × outer Ø

Technical Data


Operating voltage	max. 50 V AC/60 V DC
Rated surge voltage	1.5 kV
Operating current per contact	max. 4 A
No. of poles	3
Material group	IEC 60664-1, category I
LED display	no
Locking of ports	Screw thread (M8×1 mm) recommended torque 0.4 Nm, self-securing
Protection	IP67 inserted and tightened (EN 60529)
Protection NEMA	3, 4, 6P (UL 50E)

Commercial data

country of origin	DE
customs tariff number	85444290
EAN	4048879435543
eClass	27279220
Packaging unit	1

Sketch

Female

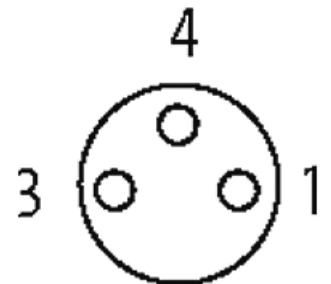

Product may differ from Image