

**M8 female receptacle rear mount**

wires PP 3x0.25 1m




Flange female


M8, 3-pole

Rear mounting

with multi-strand wire

M8, 4-pole

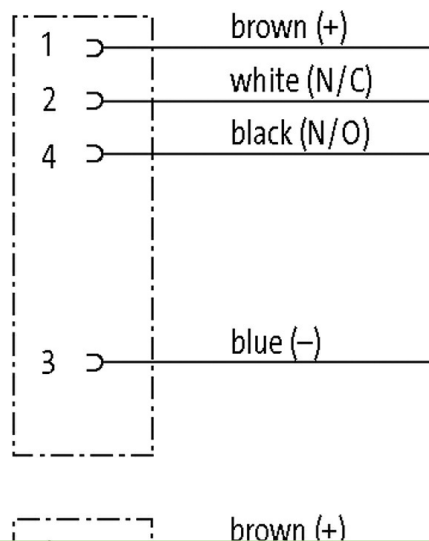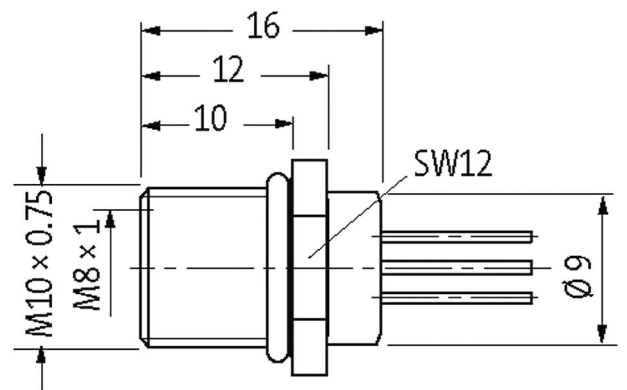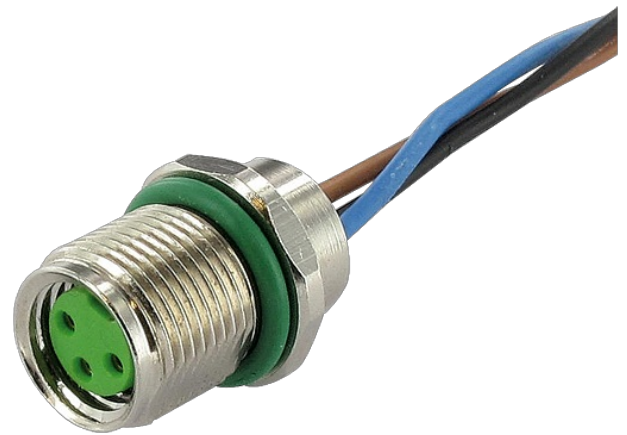**Illustration**

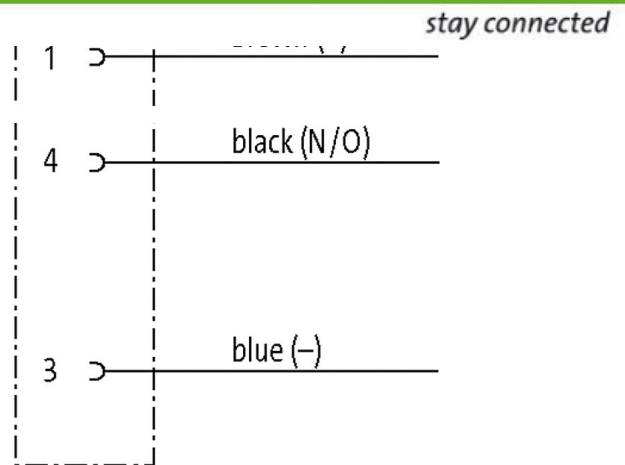

Product may differ from Image

### Approvals



### Form

Form 08575

### General data

Pollution Degree 3  
 Temperature range -25...+85 °C

### Cables

Cable number 970  
 No./diameter of wires 3 × 0.25 mm<sup>2</sup>  
 Wire isolation PP (br, bk, bl)  
 Outer Ø 1.1 mm ±5%  
 Temperature range (fixed) -40...+90 °C  
 Temperature range (mobile) -25...+90 °C  
 Bend radius (fixed) 5 × outer Ø

### Technical Data

Operating voltage max. 50 V AC/60 V DC  
 Rated surge voltage 1.5 kV  
 Operating current per contact max. 4 A  
 No. of poles 3  
 Material group IEC 60664-1, category I  
 LED display no  
 Locking of ports Screw thread (M8×1 mm) recommended torque 0.4 Nm, self-securing  
 Protection IP67 inserted and tightened (EN 60529)  
 Protection NEMA 3, 4, 6P (UL 50E)


### Commercial data

country of origin DE  
 customs tariff number 85444290  
 EAN 4048879435567  
 eClass 27279220  
 Packaging unit 1


### Sketch

*stay connected*

Female

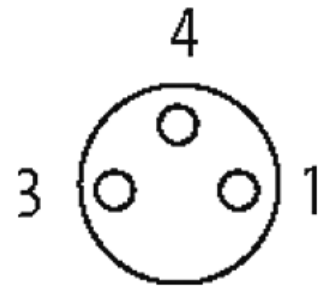

Female

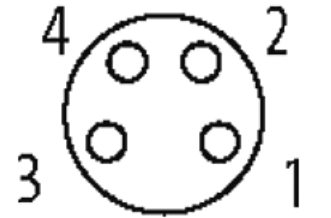

Product may differ from Image