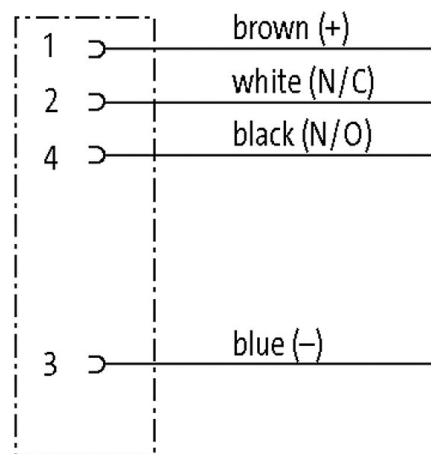
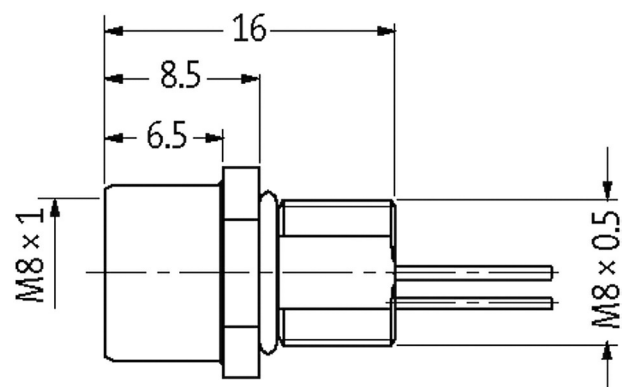
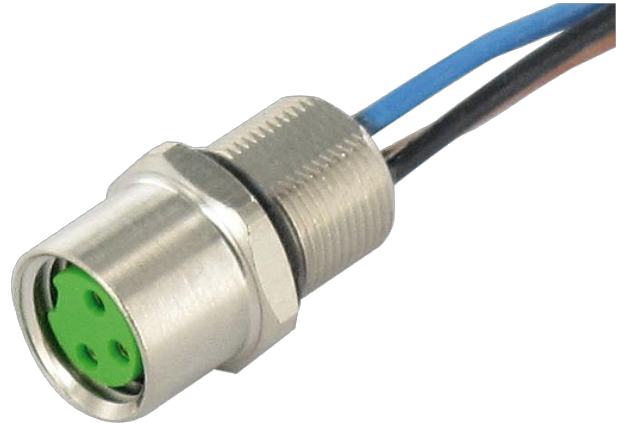


M8 FEMALE FLANGE PLUG A CODED FRONT MOUNT

PP-wires 4x0.25 0.5m

Flange female
M8, 4-pole
Front mounting
with multi-strand wire

Illustration

Product may differ from Image

Approvals

**Form**

Form 08581

General data

Temperature range -25...+85 °C

Cables

Cable number 969

No./diameter of wires 4 x 0.25 mm²

Wire isolation PP (br, bk, bl, wh)

Outer Ø 1.1 mm ±5%

Temperature range (fixed) -40...+90 °C

Temperature range (mobile) -25...+90 °C

Bend radius (fixed) 5 x outer Ø

Technical Data

Operating voltage max. 50 V AC/60 V DC

Rated surge voltage 1.5 kV

Operating current per contact max. 4 A

Locking of ports Screw thread (M8x1 mm) recommended torque 0.4 Nm, self-securing

Protection IP67 inserted and tightened (EN 60529)

Protection NEMA 3, 4, 6P (UL 50E)

Commercial data

country of origin DE

customs tariff number 85444290


EAN 4048879407670

eClass 27279220

Packaging unit 1

Sketch

Female

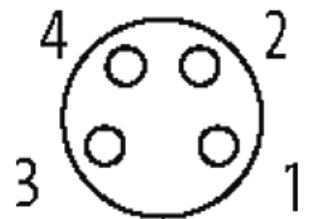

Product may differ from image