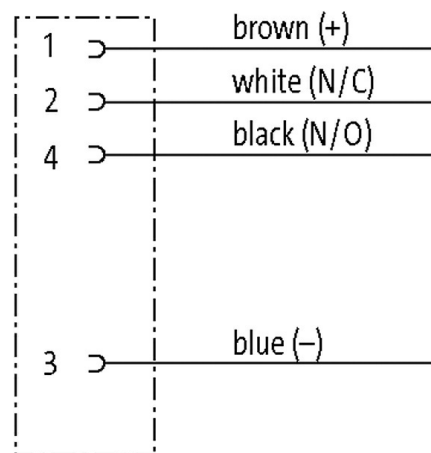
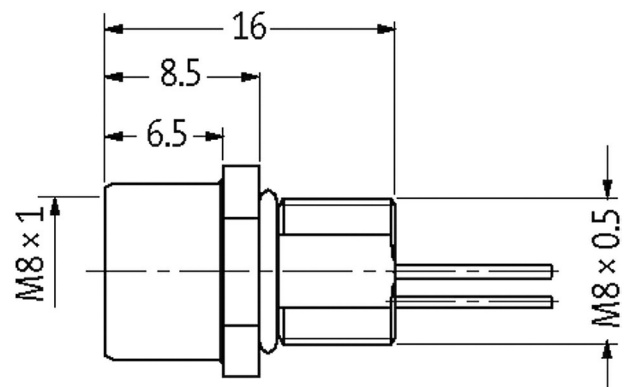
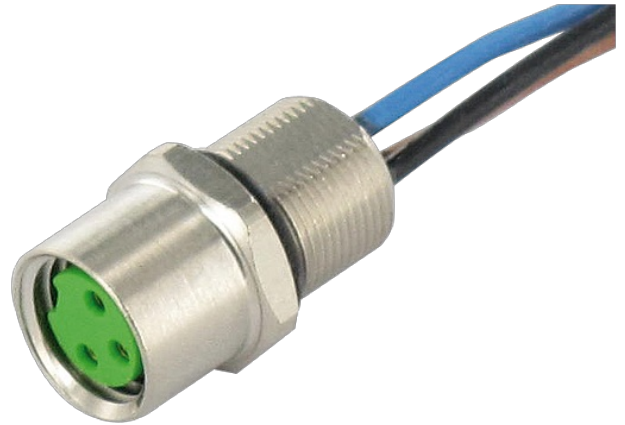


REPLACED BY 7000-08581-9690020

Flange female
M8, 4-pole
Front mounting
with multi-strand wire

Illustration

Product may differ from Image

Approvals

**Form**

Form 08581

General data

Temperature range -25...+85 °C

Cables

Cable number 971

No./diameter of wires 4 × 0.34 mm²

Wire isolation PUR

Outer Ø 1.3 mm ±5%

Bend radius (fixed) 5 × outer Ø

Temperature range (fixed) -40...+90 °C

Temperature range (mobile) -25...+90 °C

Technical Data

Operating voltage max. 50 V AC/60 V DC

Rated surge voltage 1.5 kV

Operating current per contact max. 4 A

Locking of ports Screw thread (M8×1 mm) recommended torque 0.4 Nm, self-securing

Protection IP67 inserted and tightened (EN 60529)

Protection NEMA 3, 4, 6P (UL 50E)

Commercial data

country of origin DE

customs tariff number 85444290


EAN 4048879224550

eClass 27061801

Packaging unit 1

Sketch

Female

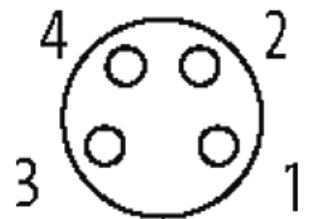

Product may differ from image