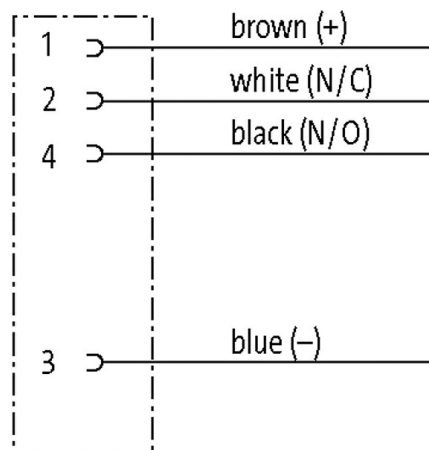
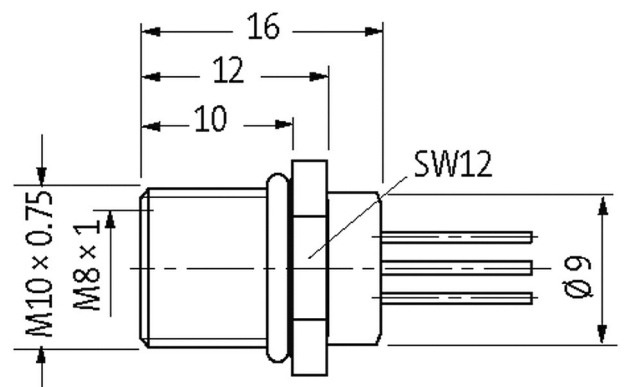


M8 FEMALE FLANGE PLUG REAR MOUNT

PP wires 4x0.25 0.5m

Flange female
M8, 4-pole
Rear mounting
with multi-strand wire

Illustration

Product may differ from Image

Approvals

**Form**

Form 08585

General data

Pollution Degree 3
 Temperature range -25...+85 °C

Cables

Cable number 969
 No./diameter of wires 4 x 0.25 mm²
 Wire isolation PP (br, bk, bl, wh)
 Outer Ø 1.1 mm ±5%
 Temperature range (fixed) -40...+90 °C
 Temperature range (mobile) -25...+90 °C
 Bend radius (fixed) 5 x outer Ø

Technical Data

Operating voltage max. 50 V AC/60 V DC
 Rated surge voltage 1.5 kV
 Operating current per contact max. 4 A
 No. of poles 4
 Material group IEC 60664-1, category I
 Locking of ports Screw thread (M8x1 mm) recommended torque 0.4 Nm, self-securing
 Protection IP67 inserted and tightened (EN 60529)
 Protection NEMA 3, 4, 6P (UL 50E)

Commercial data

country of origin DE
 customs tariff number 85444290
 EAN 4048879435383
 eClass 27279220
 Packaging unit 1

Sketch

Female



Product may differ from Image