


M12 FEMALE 90° SHIELDED WIREABLE SCREW TERM.5-pol. max.0,75mm² 6-8mm

Female 90°
M12, 5-pole
shielded
Screw terminals

Illustration

Female

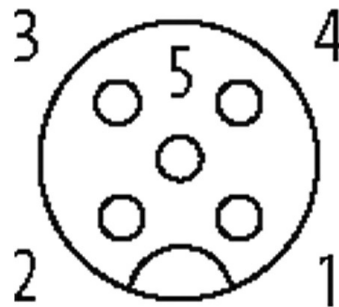

Product may differ from Image

Approvals**Form**

Form 13441

Technical Data

Operating voltage	max. 60 V AC/DC
Operating current per contact	max. 4 A
Connection cross section	max. 0.75 mm ²
Sealing range (cable Ø)	6...8 mm

Protection IP67 inserted and tightened (EN 60529)

Housing Brass, nickel plated

General data

Temperature range -40...+85 °C

Commercial data


country of origin DE

customs tariff number 85366990

EAN 4048879198776

eClass 27279221

Packaging unit 1

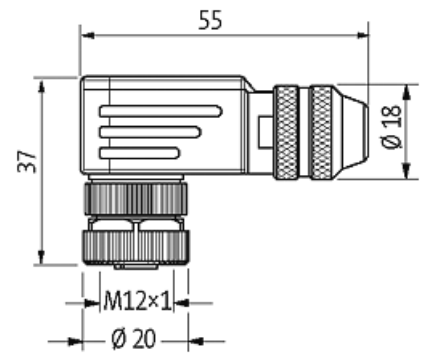Sketch

Product may differ from Image