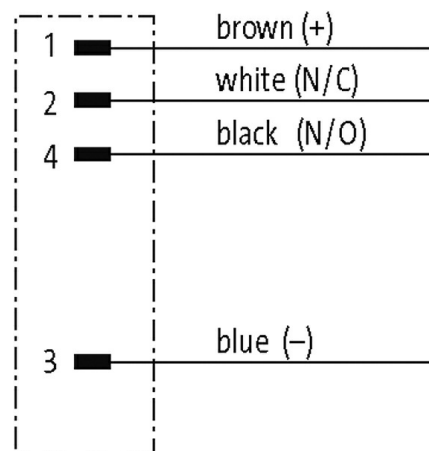
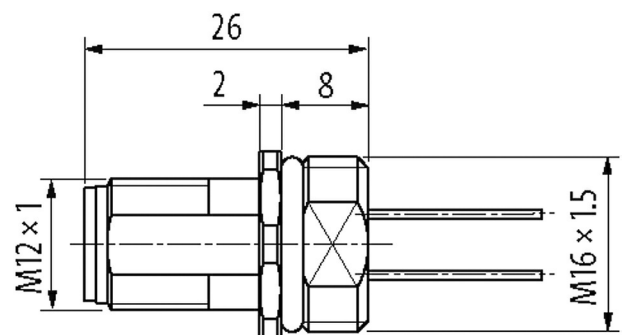
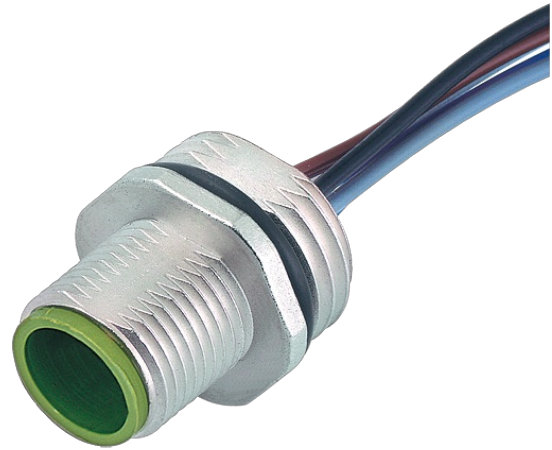


M12 male receptacle A-cod. front mount

PP-wires 4X0.34 0.2m

Flange male
M12, 4-pole
Front mounting
with multi-strand wire

Illustration

Product may differ from Image

Approvals

**Form**

Form 13501

General data

Pollution Degree 3

Temperature range -25...+85 °C

Cables

Cable number 971

No./diameter of wires 4 × 0.34 mm²

Wire isolation PUR

Outer Ø 1.3 mm ±5%

Bend radius (fixed) 5 × outer Ø

Temperature range (fixed) -40...+90 °C

Temperature range (mobile) -25...+90 °C

Technical Data

Operating voltage max. 250 V AC/DC

Rated surge voltage 2.5 kV

Operating current per contact max. 4 A

Material group IEC 60664-1, category I

Locking of ports Screw thread (M12×1 mm) recommended torque 0.6 Nm, self-securing

Compression gland M12 (SW14)

Protection IP67 inserted and tightened (EN 60529)

Protection NEMA 3, 4, 6P (UL 50E)

Locking material Zinc die casting, matte nickel plated

Commercial data

country of origin DE

customs tariff number 85444290

EAN 4048879198738

eClass 27279220

Packaging unit 1

Sketch

Male



Product may differ from Image