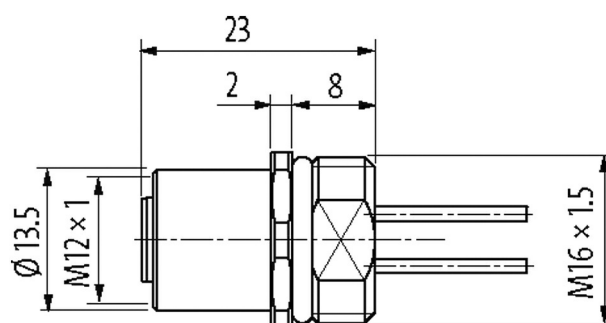



M12 FEMALE FLANGE PLUG A CODED FRONT MOUNT

PVC-wires 8x0,25 0.5m

Flange female
M12, 8-pole
Front mounting
with multi-strand wire

Illustration

Female

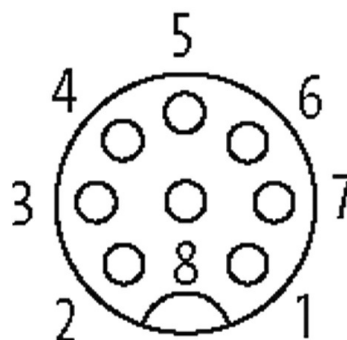

Product may differ from Image

Approvals

**Form**

Form 17181

General data

Temperature range -25...+85 °C

Cables

Cable number 903

No./diameter of wires 8 × 0.25 mm²

Wire isolation PVC (bl, wh, gn, ye, gr, pk, rd, br)

Outer Ø 1.15 mm ±5%

Bend radius (fixed) 12 × outer Ø

Temperature range (fixed) -40...+105 °C

Temperature range (mobile) -5...+105 °C

Technical Data

Operating voltage max. 30 V AC/DC

Rated surge voltage 0.8 kV

Operating current per contact max. 2 A

Locking of ports Screw thread (M12×1 mm) recommended torque 0.6 Nm, self-securing

Protection IP67 inserted and tightened (EN 60529)

Protection NEMA 3, 4, 6P (UL 50E)

Commercial data

country of origin DE

customs tariff number 85444290

EAN 4048879295048

eClass 27279220

Packaging unit 1

Sketch

Product may differ from Image