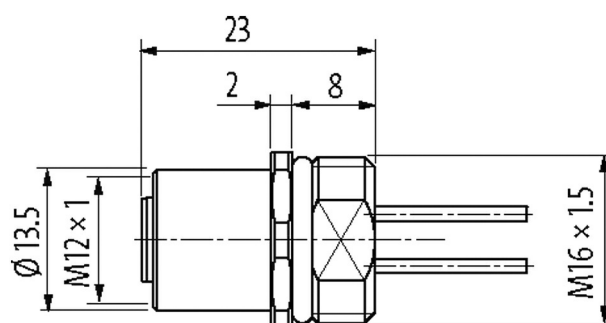



M12 FEMALE FLANGE PLUG A CODED FRONT MOUNT

PP-wires 8x0,25 0.5m

Flange female
M12, 8-pole
Front mounting
with multi-strand wire

Illustration

Female

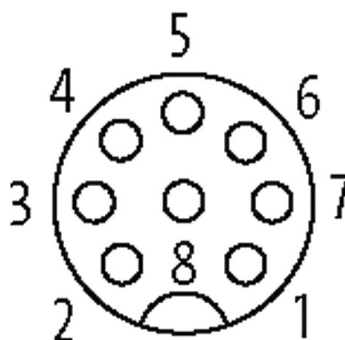

Product may differ from Image

Approvals

**Form**

Form	17181
------	-------

Cables

Cable number	973
No./diameter of wires	8 × 0.25 mm ²
Wire isolation	PUR (wh, br, gn, ye, gr, pk, bl, rd)
Outer Ø	1.25 mm ±5%
Bend radius (fixed)	10 × outer Ø
Temperature range (fixed)	-40...+90 °C
Temperature range (mobile)	-25...+90 °C

Technical Data

Operating voltage	max. 30 V AC/DC
Rated surge voltage	0.8 kV
Operating current per contact	max. 2 A
Locking of ports	Screw thread (M12×1 mm) recommended torque 0.6 Nm, self-securing
Protection	IP67 inserted and tightened (EN 60529)
Protection NEMA	3, 4, 6P (UL 50E)

General data

Temperature range	-25...+85 °C
-------------------	--------------

Commercial data

country of origin	DE
customs tariff number	85444290
EAN	4048879295093
eClass	27279220
Packaging unit	1

Sketch

Product may differ from image