

**MOSA VALVE PLUG FORM A 18MM FIELD-WIREABLE**

Form A (18 mm)



0...250 V AC/300 V DC

without components


IDC terminals


Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

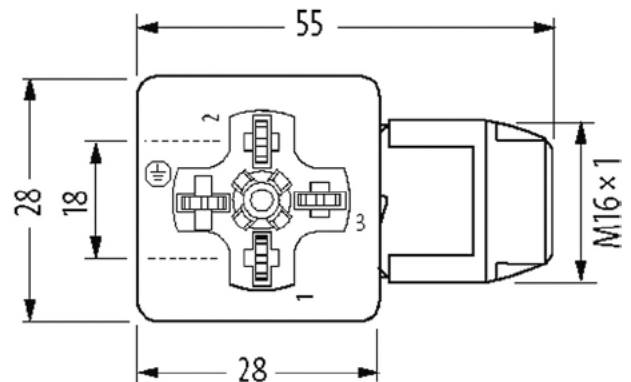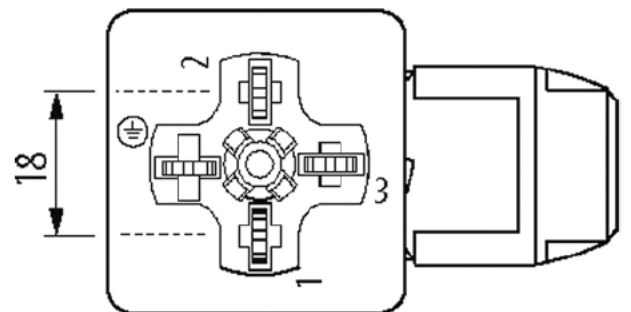[Link to Product](#)**Illustration**

 Height: 40 mm



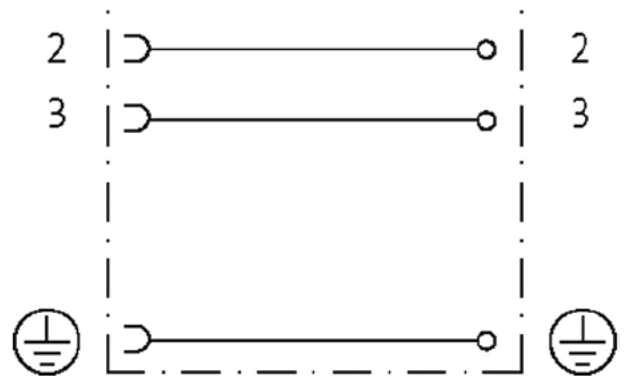

Produced in Germany

### Approvals



### Form

Form 8 6

### General data

Dimensions H×W×D 40×28×55 mm

Mounting set M 6× mm

Temperature range 25 +85 °C

### Technical Data

Operating voltage 0 250 V AC/300 V DC

Operating current per contact max 6 A

Connection cross section 0.5 0 mm<sup>2</sup> (conductor diameter min 0.5 mm)

Outer wire Ø 6.20 mm

Sealing range (cable Ø) 5.5 8 mm

Protection P67 inserted and tightened (EN 60529)

### Commercial data

country of origin CZ

customs tariff number 85366990

EAN 4048879 8965

eClass 2727922

Packaging unit