

## MOSA VALVE PLUG FORM A 18MM FIELD-WIREABLE

Form A (18 mm)

24 V AC/DC  $\pm 25\%$

LED and suppressor diode



IDC terminals

Plastic housings with good resistance against chemicals and oils.


The resistance to aggressive media should be individually tested for your application. Further details on request.


### [Link to Product](#)

#### Illustration

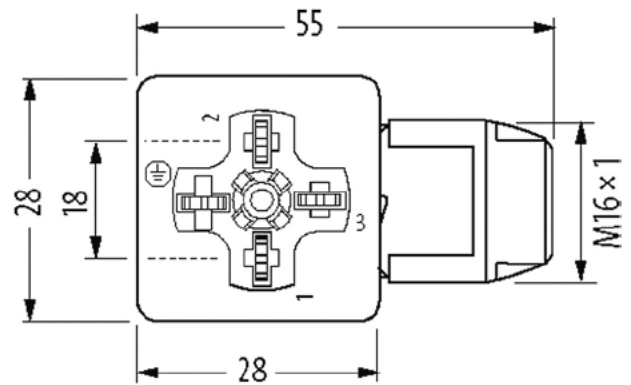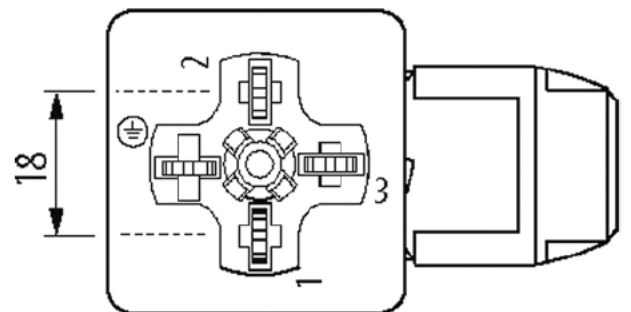

Height: 40 mm

 

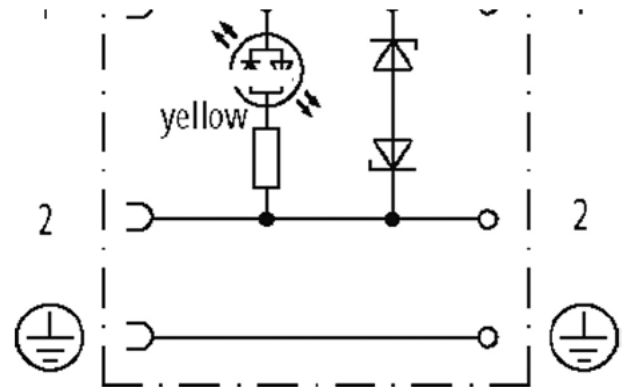

Product may differ from image

### Form

Form 8 8

### General data

Dimensions H×W×D 40×28×55 mm  
 Mounting set M 6× mm  
 Temperature range 25 +85 °C

### Technical Data

Operating voltage 24 V AC/DC 25%  
 Operating current per contact max 6 A  
 Switch off peak max 53 V  
 Connection cross section 0.5 – 0 mm<sup>2</sup> (conductor diameter min 0.5 mm)  
 Sealing range (cable Ø) 5.5 – 8 mm  
 Outer wire Ø 6.2 – 0 mm  
 Protection P67 inserted and tightened (EN 60529)

### Commercial data

country of origin CZ  
 customs tariff number 85366990  
 EAN 4048879 89644  
 eClass 2727922  
 Packaging unit