


M12 MALE FLANGE PLUG C CODED FRONT MOUNT

3X0.75 0.5m

Flange male
M12, 3-pole
C-coded
Front mounting
with multi-strand wire

[Link to Product](#)

Illustration

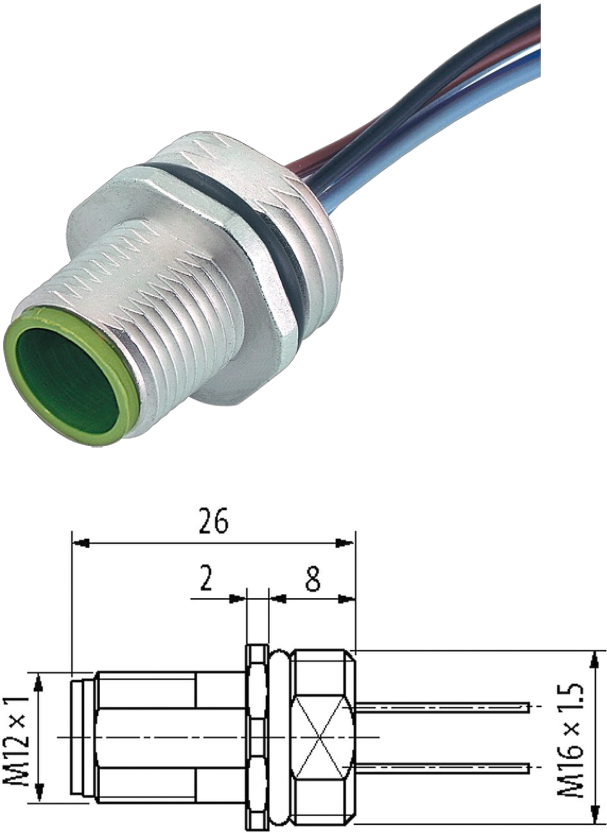

Product may differ from Image

Approvals



Form

Form 20201

General data

Pollution Degree	3
Material (contact)	Copper alloy
Material (contact surface)	Au
Temperature range	-25...+85 °C

Cables

Cable number	930
No./diameter of wires	3 × 0.75 mm ²
Wire isolation	PP (bk num, gnye)
Outer Ø	1.85 mm ±5%
Bend radius (fixed)	5 × outer Ø
Bend radius (moving)	10 × outer Ø
Temperature range (fixed)	-40...+80 °C
Temperature range (mobile)	-25...+80 °C

Technical Data


Operating voltage	max. 250 V AC/DC
Rated surge voltage	2.5 kV
Operating current per contact	max. 4 A
No. of poles	3
Material group	IEC 60664-1, category I
Coding	C-coded
LED display	no
Locking of ports	Screw thread (M12×1 mm) recommended torque 0.6 Nm, self-securing
Compression gland	M12 (SW14)
Protection	IP67 inserted and tightened (EN 60529)
Protection NEMA	3, 4, 6P (UL 50E)
Locking material	Zinc die casting, matte nickel plated

Commercial data

country of origin	DE
customs tariff number	85444290
EAN	4048879385725
eClass	27279220
Packaging unit	1

Sketch

Male

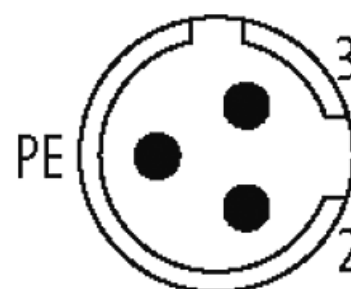

Product may differ from Image