


M12 FEMALE FLANGE PLUG C CODED FRONT MOUNT

PP-wires 3X0.75 1m

Flange female
M12, 3-pole
C-coded
Front mounting
with multi-strand wire

[Link to Product](#)

Illustration

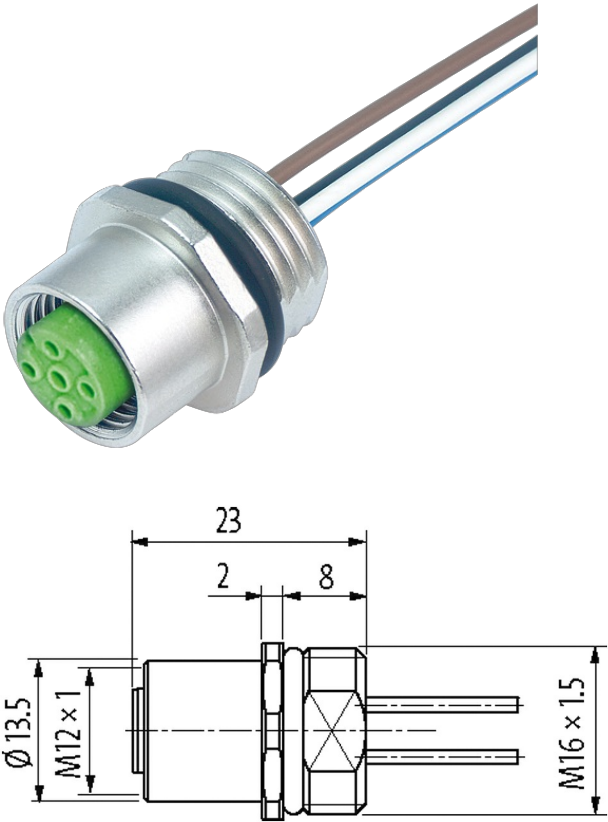

Product may differ from Image

Approvals



Form

Form 20221

General data

Pollution Degree	3
Temperature range	-25...+85 °C

Cables

Cable number	930
--------------	-----


No./diameter of wires	3 × 0.75 mm ²
Wire isolation	PP (bk num, gnye)
Outer Ø	1.85 mm ±5%
Bend radius (fixed)	5 × outer Ø
Bend radius (moving)	10 × outer Ø
Temperature range (fixed)	-40...+80 °C
Temperature range (mobile)	-25...+80 °C

Technical Data

Operating voltage	max. 250 V AC/DC
Operating current per contact	max. 4 A
Rated surge voltage	2.5 kV
No. of poles	3
Material group	IEC 60664-1, category I
Coding	C-coded
LED display	no
Locking of ports	Screw thread (M12×1 mm) recommended torque 0.6 Nm, self-securing
Compression gland	M12 (SW14)
Protection	IP67 inserted and tightened (EN 60529)
Protection NEMA	3, 4, 6P (UL 50E)
Locking material	Brass, nickel plated

Commercial data

country of origin	DE
customs tariff number	85444290
EAN	4048879380102
eClass	27279220
Packaging unit	1

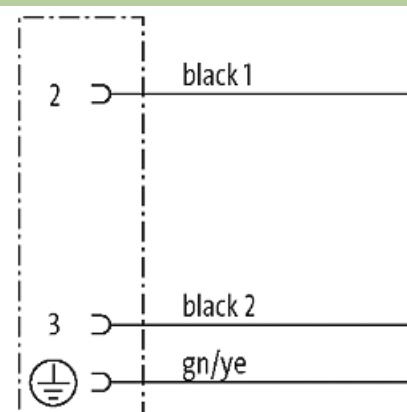Sketch

Product may differ from Image