


M23 female 0° 19 pole with cable

PUR 12x0.34+3x0.75 gray, drag chain 15m

Female straight  
M23, 19-pole  
15-pole used  
for 6-way distribution boxes, 5-pole  
Further cable lengths on request.  
Plastic housings with good resistance against chemicals and oils.  
The resistance to aggressive media should be individually tested for your application. Further details on request.

Link to Product

Illustration

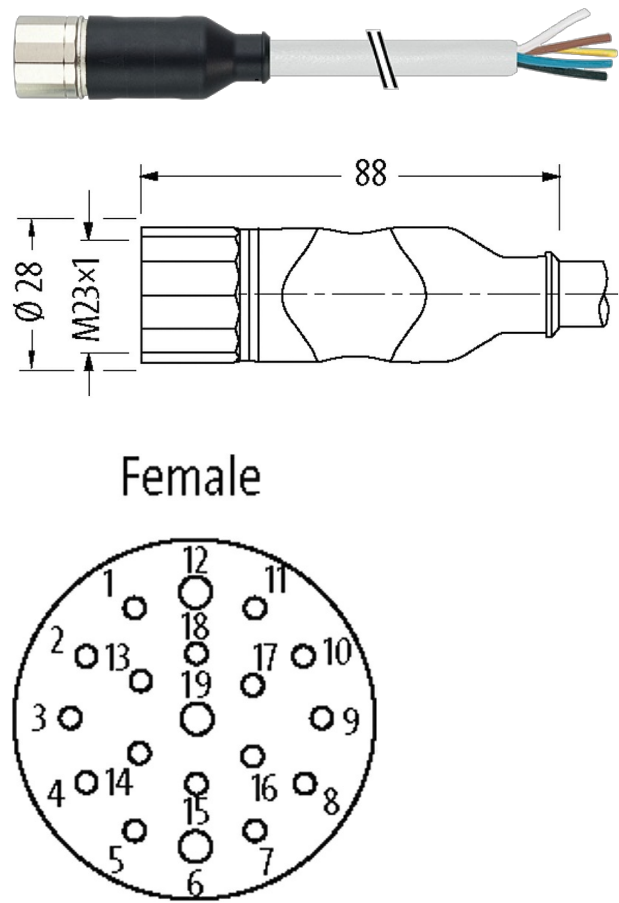

Product may differ from Image

| Form                  |                                                                                |
|-----------------------|--------------------------------------------------------------------------------|
| Form                  | 23231                                                                          |
| General data          |                                                                                |
| Temperature range     | -25...+85 °C, depending on cable quality                                       |
| Cables                |                                                                                |
| Cable number          | 388                                                                            |
| No./diameter of wires | 12× 0.34 + 3× 0.75 mm²                                                         |
| Wire isolation        | PVC (yebr, rd, grpk, wh, rdbl, gn, whgn, ye, brgn, gr, whye, pk, br, gnye, bl) |

|                            |              |
|----------------------------|--------------|
| C-track properties         | 2 Mio.       |
| Jacket Color               | gray         |
| Material (jacket)          | PUR/PVC      |
| Outer Ø                    | 9.8 mm ±5%   |
| Bend radius (fixed)        | 10× outer Ø  |
| Bend radius (moving)       | 12× outer Ø  |
| Temperature range (fixed)  | -30...+80 °C |
| Temperature range (mobile) | -5...+70 °C  |
| Color (jacket)             | gray         |

**Technical Data**

|                               |                                                                  |
|-------------------------------|------------------------------------------------------------------|
| Operating voltage             | max. 125 V AC/DC                                                 |
| Operating current per contact | max. 7.5 A                                                       |
| Locking of ports              | Screw thread (M23×1 mm) recommended torque 2.0 Nm, self-securing |
| Compression gland             | M23 (SW27)                                                       |
| Protection                    | IP65 and IP67 when plugged and screwed down (EN 60529)           |
| Locking material              | Brass, nickel plated                                             |
| Material                      | PUR                                                              |

**Commercial data**

|                       |               |
|-----------------------|---------------|
| country of origin     | DE            |
| customs tariff number | 85444290      |
| EAN                   | 4048879188098 |
| eClass                | 27279218      |
| Packaging unit        | 1             |